


DETAILS

 
Product Number	CA13477_STRADA-FT
Family	Strada-Forward
Type	Assembly
Color	clear
Diameter	15,4 x 19,6 mm
Height	8.3 mm
Style	rectang
Optic Material	PMMA
Holder Material	
Fastening	screw, pin, tape
Status	ready
ROHS Compliant	Yes
Date Updated	14/07/2014

OPTICAL PROPERTIES


LED	Viewing	Light	Efficiency	cd/lm	Connector
	Angle	Beam			
XP-G2	Asymmetric deg	Asymmetric	87 %	0.530	-
XT-E	Asymmetric deg	Asymmetric	87 %	0.490	-
Oslon Square PC	sim: Asymmetric	Asymmetric	sim: 93 %	sim: 0.000	-
LH351Z	Asym deg	Asymmetric	87 %	0.530	-
Fortimo FastFlex LED board 2x8/757 DS	Asymmetric deg	Asymmetric	86 %	0.530	-



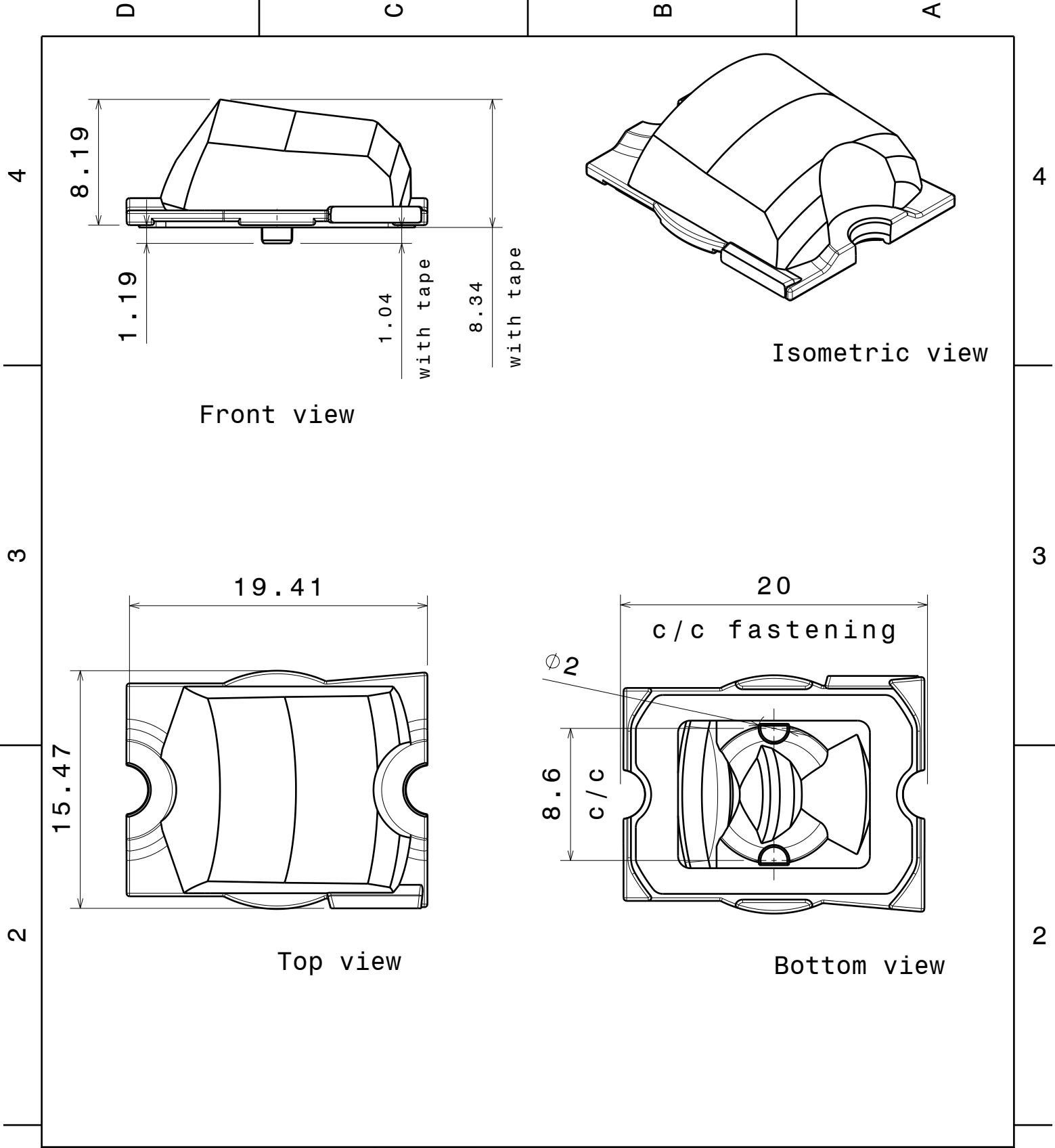


Tolerances if not otherwise shown According to DIN ISO 2768-1 Linear measures: Up to 30mm class M, otherwise class C. According to DIN ISO 2768-2 Form and position: class L		LEDiL		Ledil Oy Salorankatu 10 FIN 24240 SALO Finland	
THIRD ANGLE PROJECTION: 		DRAWING TITLE STRADA-FT			
This drawing is the property of LEDiL Oy. It may not be reproduced, copied or communicated without a written agreement with LEDiL Oy."		SIZE	PART NUMBER		
		A4	-		
		SCALE	3:1	WEIGHT	-
					SHEET 1 / 1


Luminaire: LEDiL Oy CA13477_STRADA-FT_(XP-G2) Eff.87.4%
Lamps: 1 x CREE_XP-G2_(XPGBWT-L1-0000-00FE4)_100.96lm@250mA_P=0.755898W_I=249.9mA

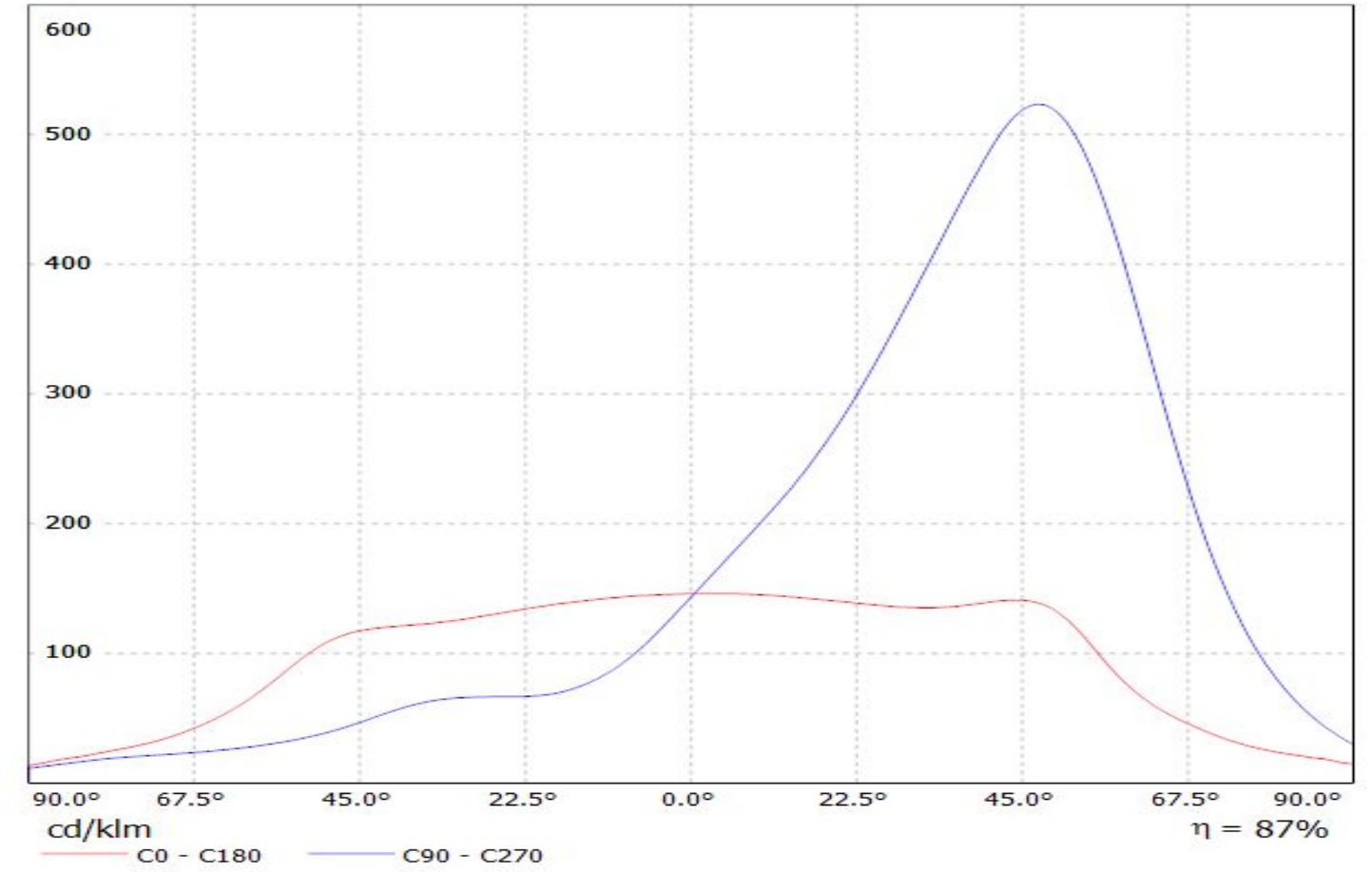

Luminaire: LEDiL Oy CA13477_STRADA-FT_(XT-E) Eff.87.2%
Lamps: 1 x Cree XT-E_(XTEAWT-00-0000-00000HBE8)
_75.4045lm@250mA_CCT=2811K_P=0.789284W_I=249.9mA

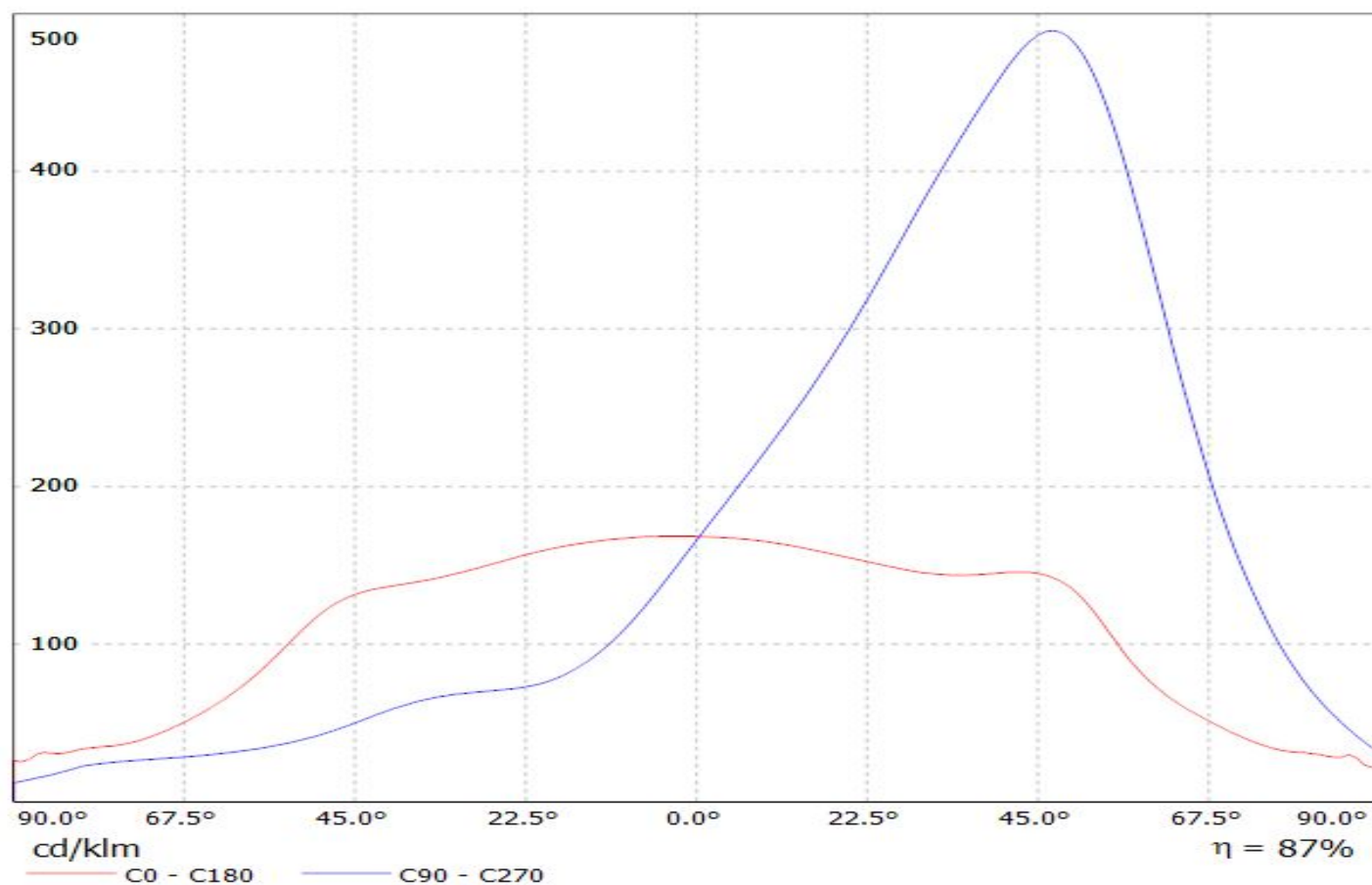


Luminaire: LEDiL Oy CA13477_STRADA-FT_(LH351Z) Eff.87.1%
Lamps: 1 x SAMSUNG_LH351Z_90.238lm@250mA_P=0.747026W_I=249.9mA

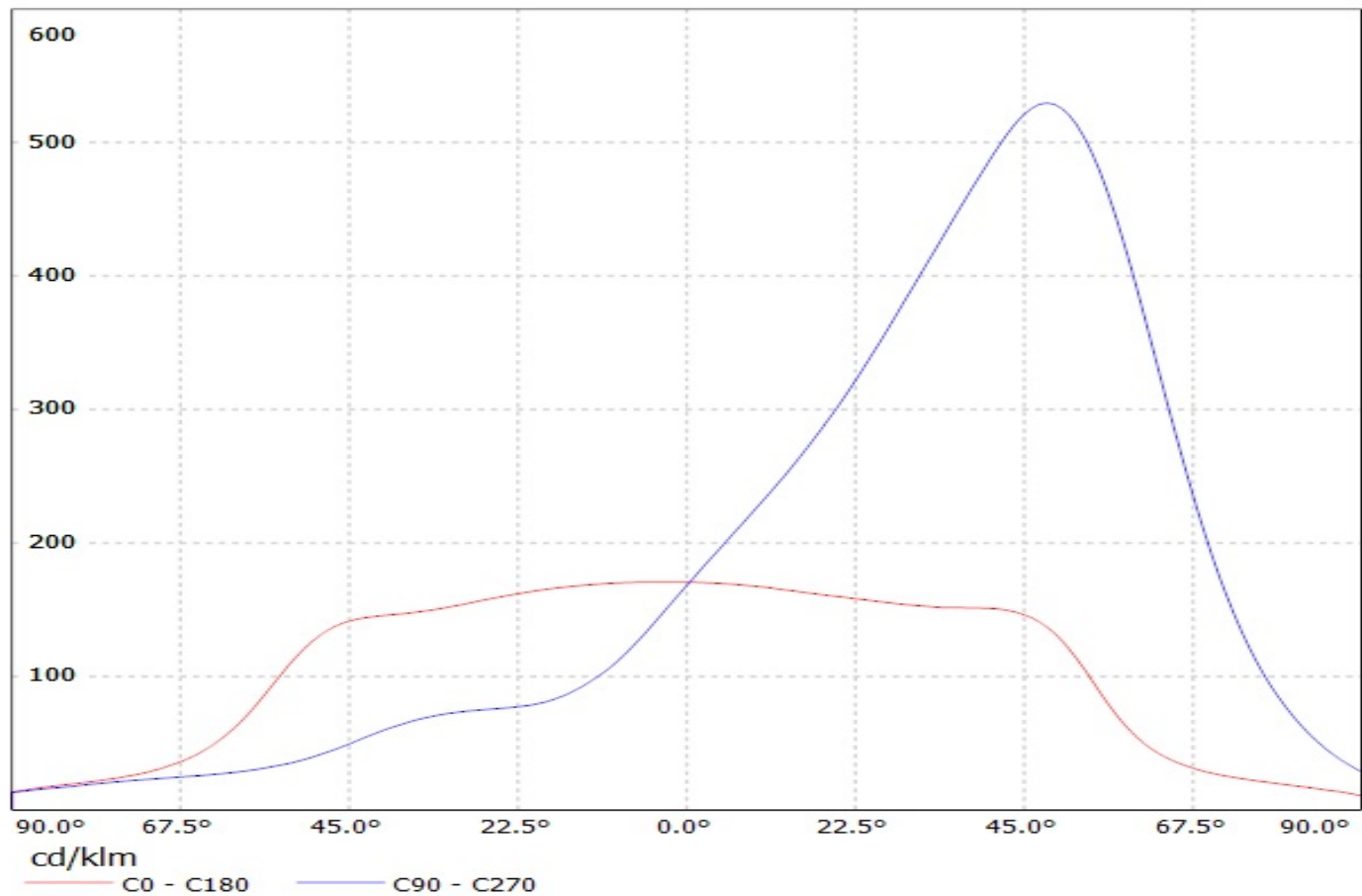


**Ledil CA13477_STRADA-FT_(Fortimo_FastFlex_LED_board 2x8-757_DS_G3) /
LDC (Linear)**

Luminaire: Ledil CA13477_STRADA-FT_(Fortimo_FastFlex_LED_board 2x8-757_DS_G3)
Lamps: 1 x Philips_Fortimo_FastFlex_LED_board 2x8/757_DS_G3_(XP-G2)
_3428.78lm@500mA_P=23.7W_I=0.5A

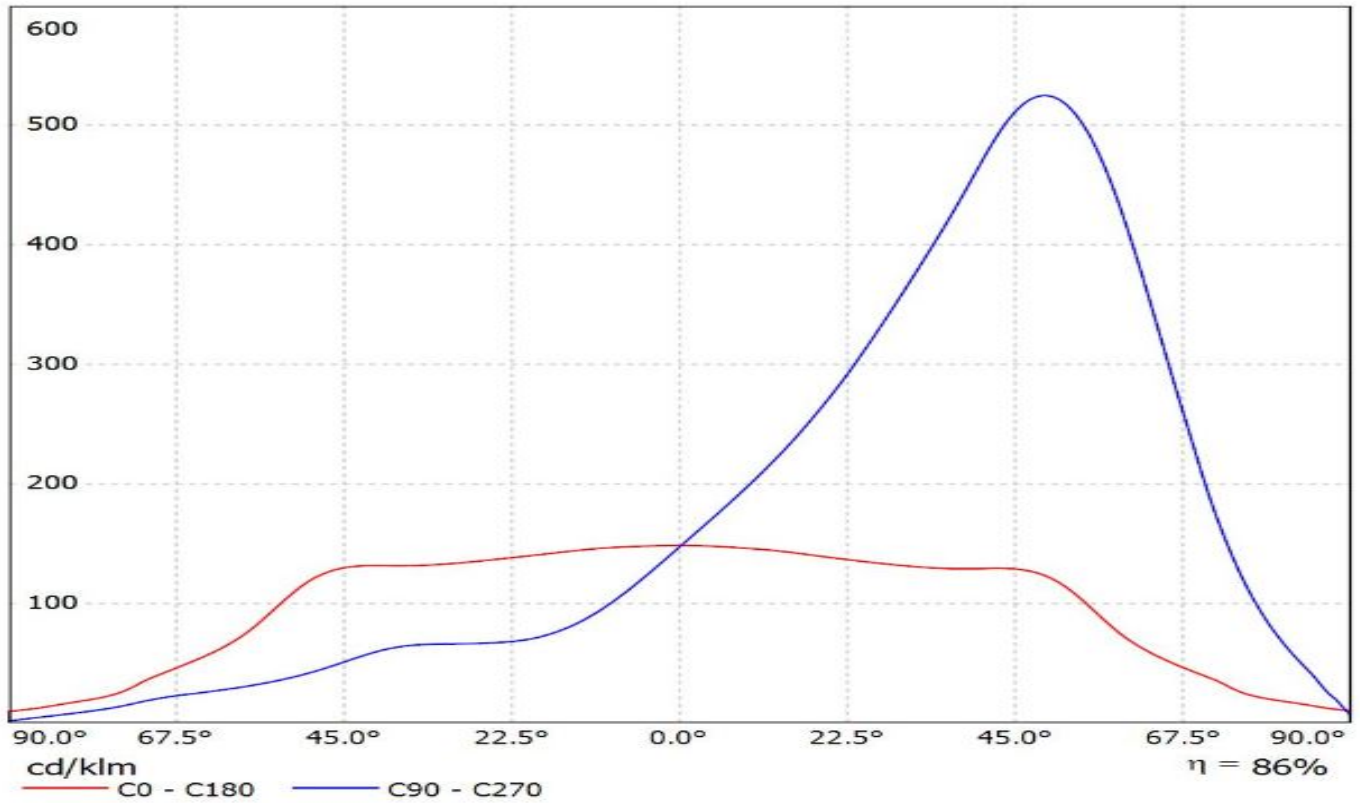


Luminaire: LEDiL Oy CA13477_STRADA-FT_(XP-G2) Eff.87.4%

Lamps: 1 x CREE_XP-G2_(XPGBWT-L1-0000-00FE4)_100.96lm@250mA_P=0.755898W_I=249.9mA

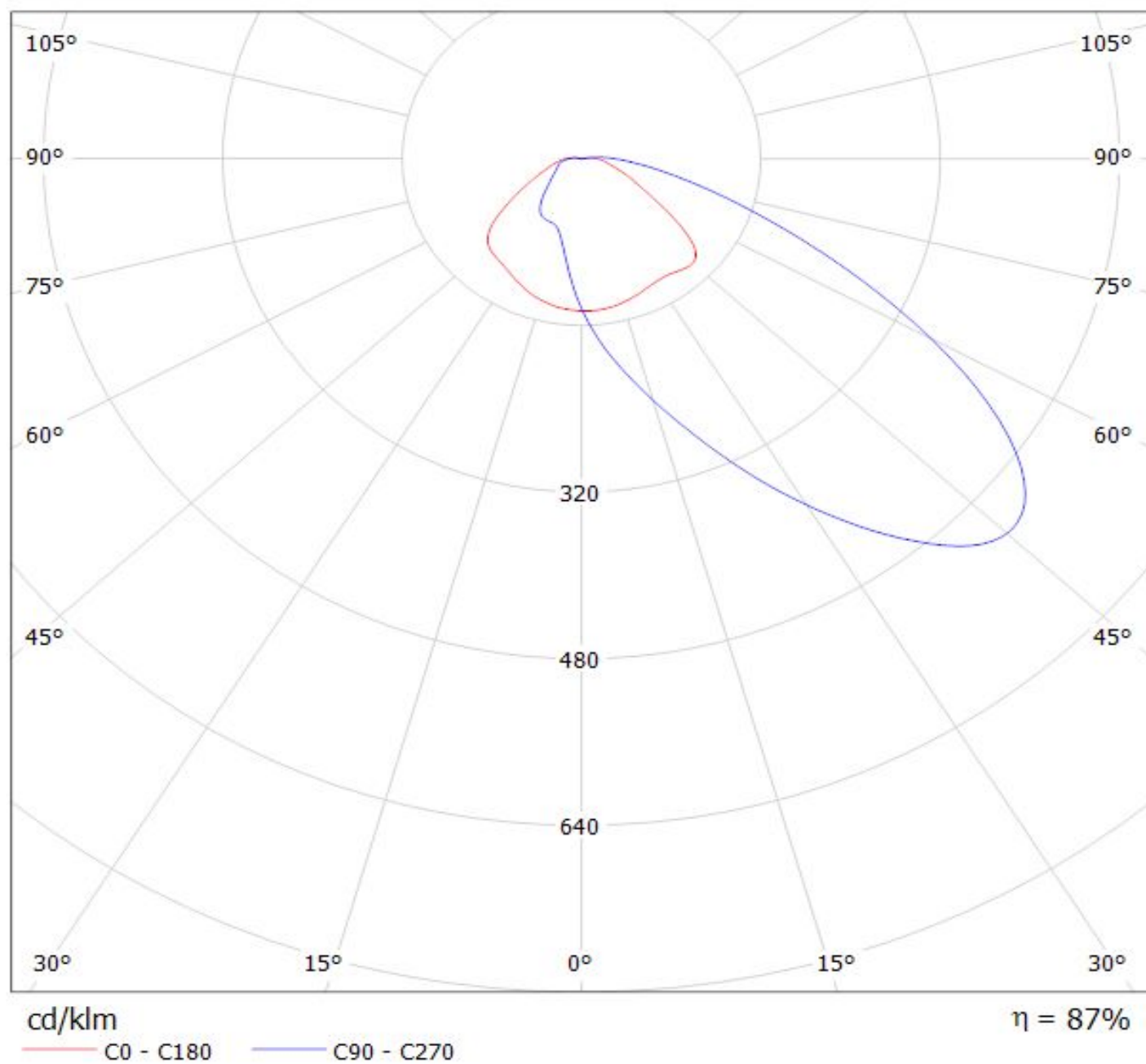


Luminaire: LEDiL Oy CA13477_STRADA-FT_(XT-E) Eff.87.2%
Lamps: 1 x Cree XT-E_(XTEAWT-00-0000-00000HBE8)
_75.4045lm@250mA_CCT=2811K_P=0.789284W_I=249.9mA

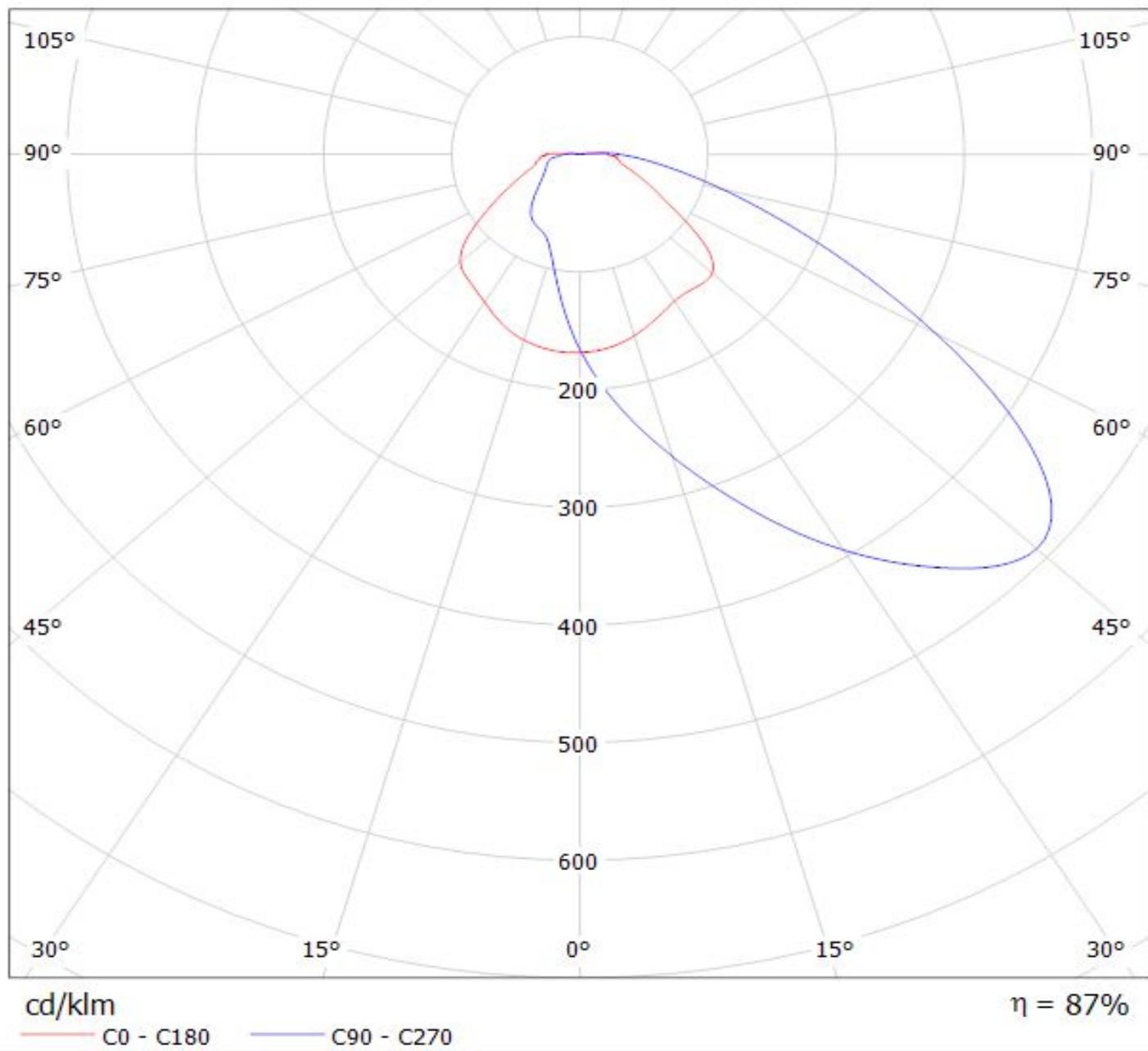


Luminaire: LEDiL Oy CA13477_STRADA-FT_(LH351Z) Eff.87.1%

Lamps: 1 x SAMSUNG_LH351Z_90.238lm@250mA_P=0.747026W_I=249.9mA

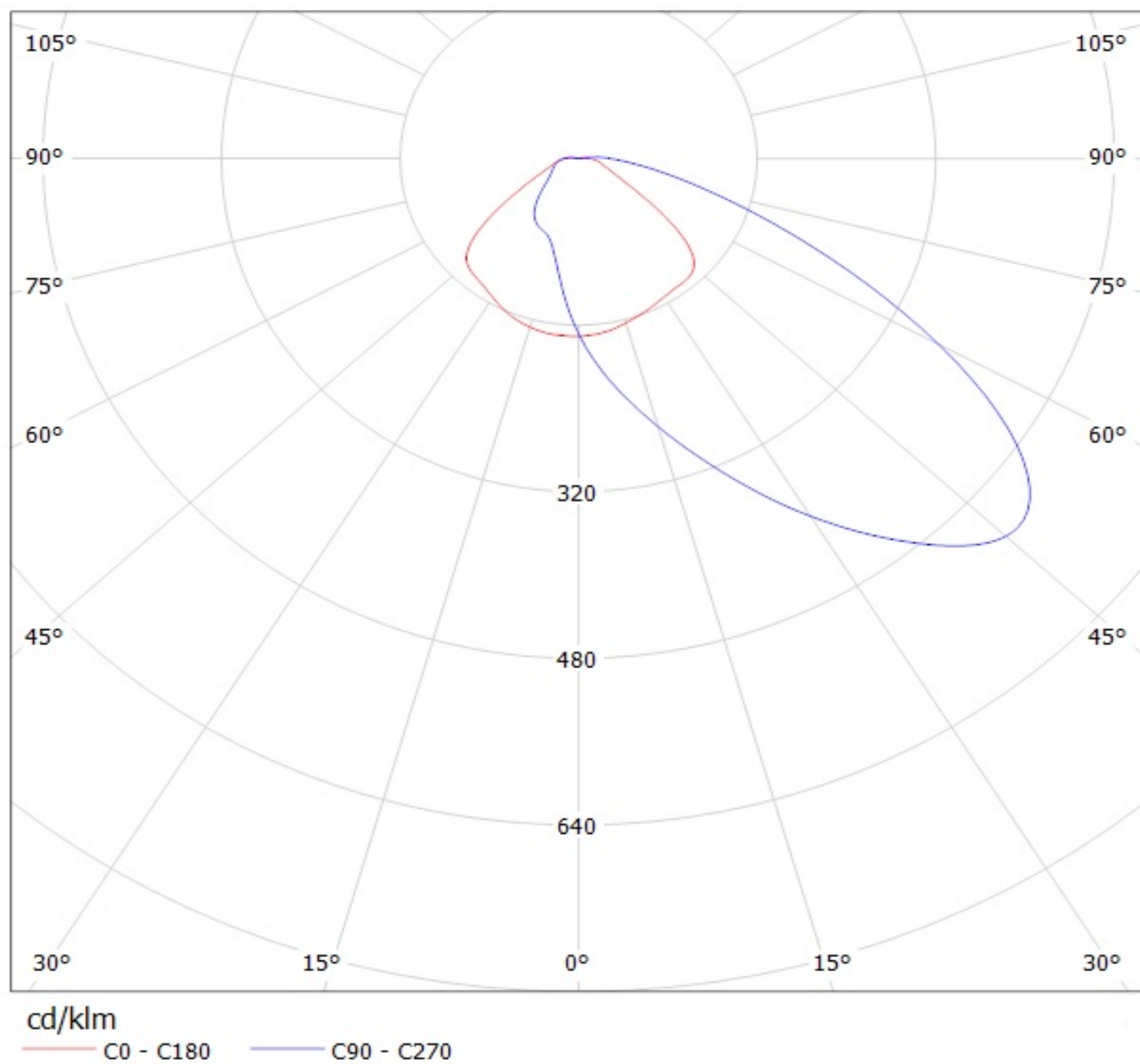

**Ledil CA13477_STRADA-FT_(Fortimo_FastFlex_LED_board 2x8-757_DS_G3) /
LDC (Polar)**

Luminaire: Ledil CA13477_STRADA-FT_(Fortimo_FastFlex_LED_board 2x8-757_DS_G3)
Lamps: 1 x Philips_Fortimo_FastFlex_LED_board 2x8/757_DS_G3_(XP-G2)
_3428.78lm@500mA_P=23.7W_I=0.5A

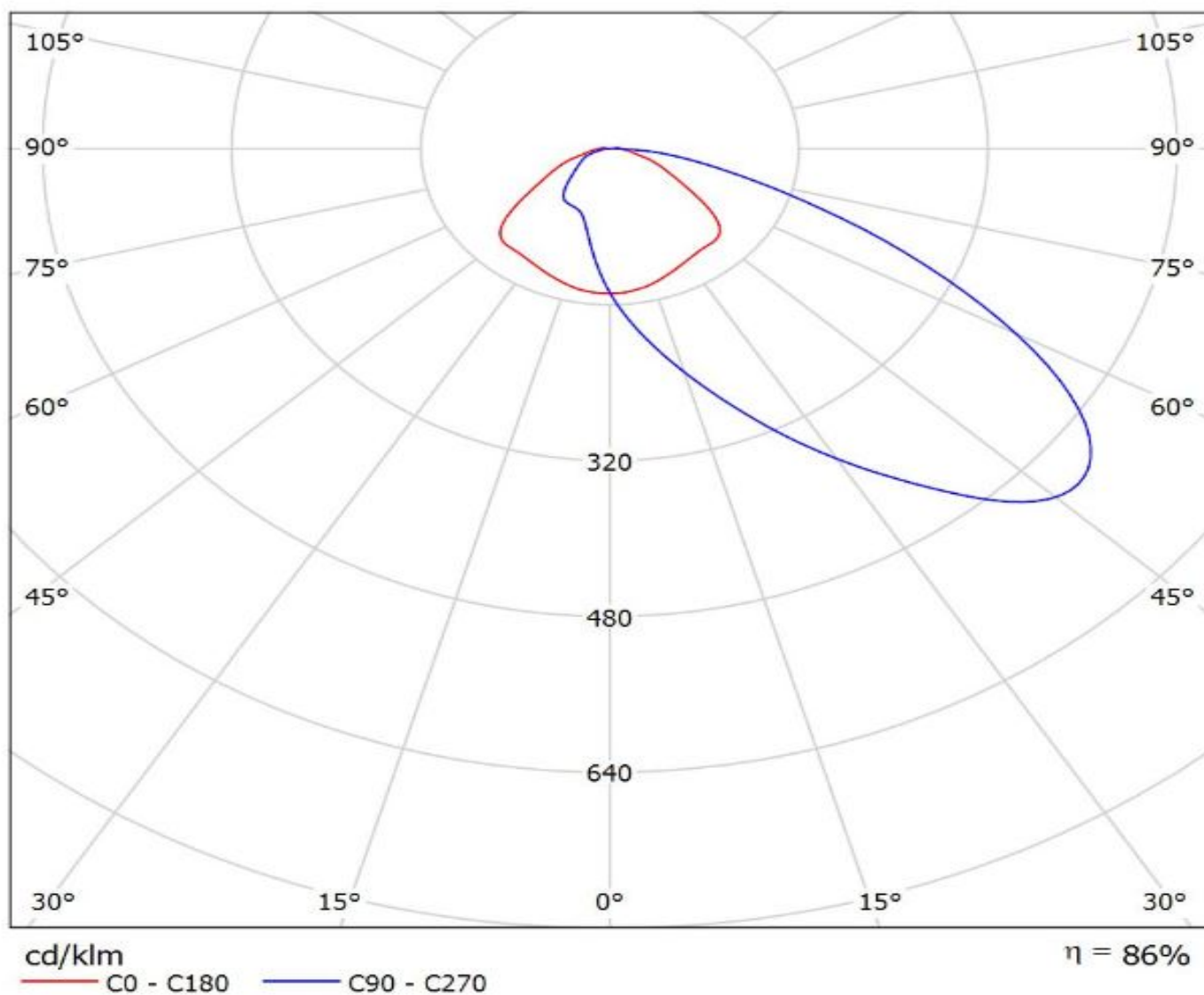

NOTE: The typical divergence will be changed by different color, chip size and chip position tolerance. The typical total divergence is the full angle measured where the luminous intensity is half of the peak value.