



This is a sample photo.


**ORDER SYMBOL:** PC 125/100 HG

**EL.number** **EAN:** 6418074022110  
 Sweden:  
 Denmark:  
 Finland: 3420333

**INCLUDING:**  
 Enclosure cover with cover screws, body with mounting screws and gasket.

**APPROVALS:**  
 USA: NEMA 4, 4X, 12; UL 94-V2  
 EURO: IP 67; UL 94-V2  
 OTHERS: IEC 529

FIBOX MNX PC

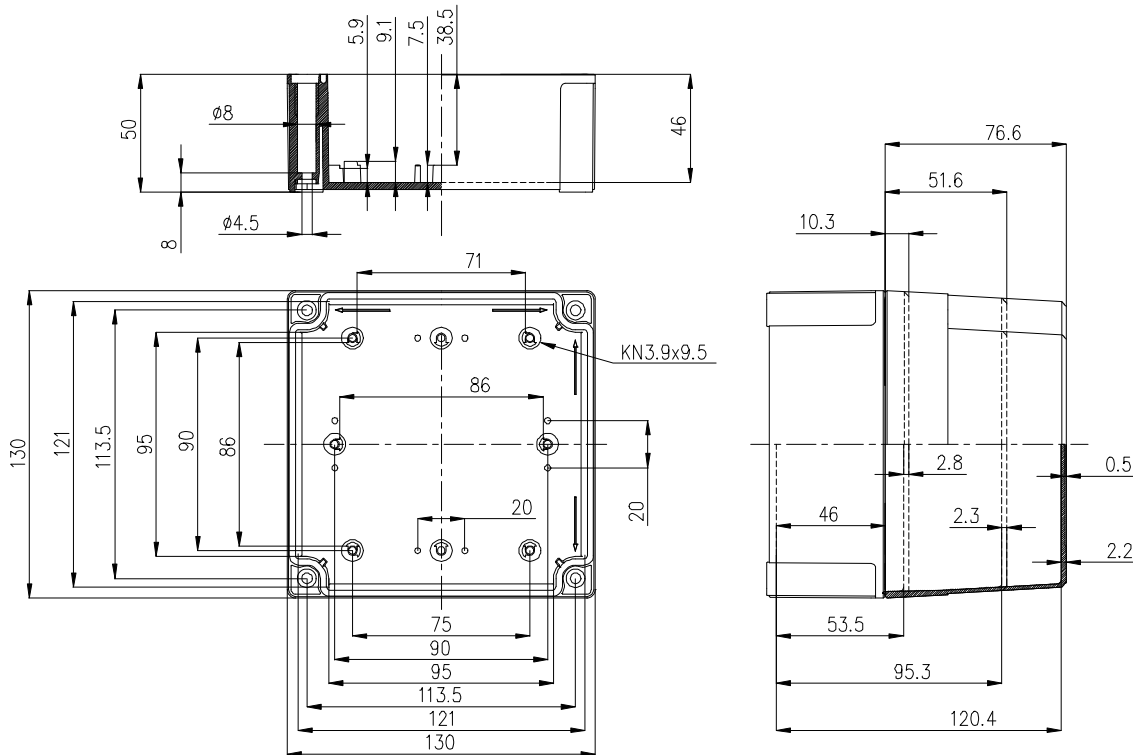

**TECHNICAL INFORMATION:**

Standard colour: RAL 7035  
 Ingress protection: IP 67 (IEC 529)  
 Flame resistance:

Temp.range in cont. use: Max. +80 °C  
 Temp. range of material: - 40 °C - + 120 °C

**ACCESSORIES**

Fastening lug	FP 22046	DIN-Rail	MIV 10
Grey Screw set	MBS HH	DIN-Rail	MIV 15
Grey Screw set	MBS HL	DIN-Rail	MIV 20
Grey Screw set	MBS LH	DIN-Rail	MIV 5
Grey Screw set	MBS LL		
DIN-Rail	MIN 10		
DIN-Rail	MIN 15		
DIN-Rail	MIN 20		
DIN-Rail	MIN 5		