

Datasheet

Miniature Toggle Switch

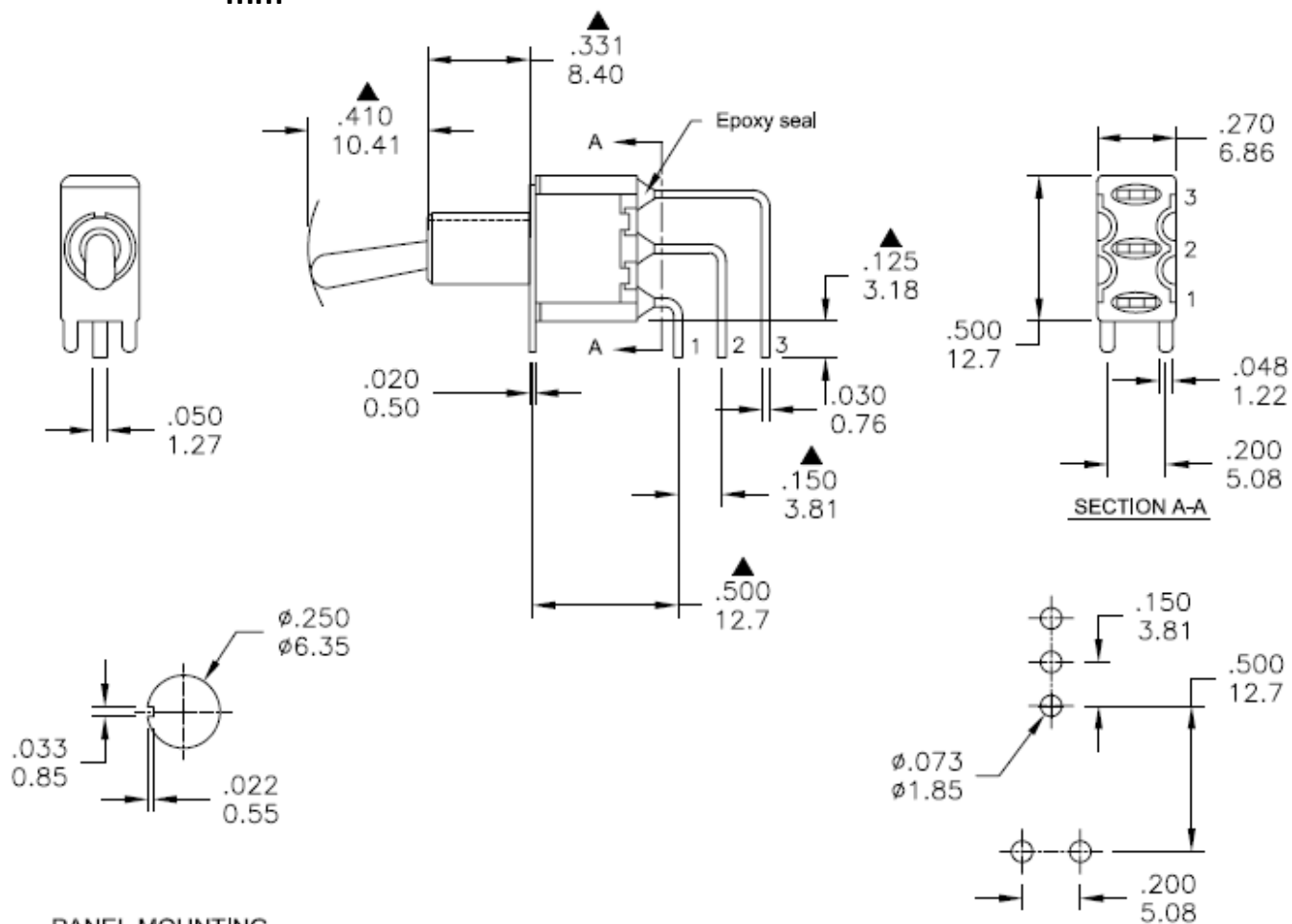
RS Stock number 734-7078



Specifications:

 
 
MECHANICAL LIFE:	40,000 make-and-break cycles.
CONTACT RESISTANCE:	10mΩ max. initial @ 2-4VDC 100mA for both silver and gold plated contacts
INSULATION RESISTANCE:	1000MΩmin.
DIELECTRIC STRENGTH:	1,000Vrms min. @ sea level.
OPERATING TEMPERATURE:	-30°C to 85°C.
CASE:	Dially phthalate (DAP) UL94v-0)
ACTUATOR:	Brass, chrome plated
Bushing:	Brass, nickel plated
Housing:	Stainless steel
CONTACT/TERMINAL:	Silver or gold plated
Switch Support:	Brass, tin plated

Dimensions – inch mm



PANEL MOUNTING

P.C. MOUNTING

Model No.	POS.1	POS.2	POS.3
			
1MS1	ON	NONE	ON
Term. Comm.	2-3	OPEN	2-1
SCHEMATIC			

SWITCH FUNCTION