


Tilt Switch - Non Mercury contacts
Part Number : S1234
Product Data Sheet

PICTURE



✓ RoHS Compliant

DIMENSIONS

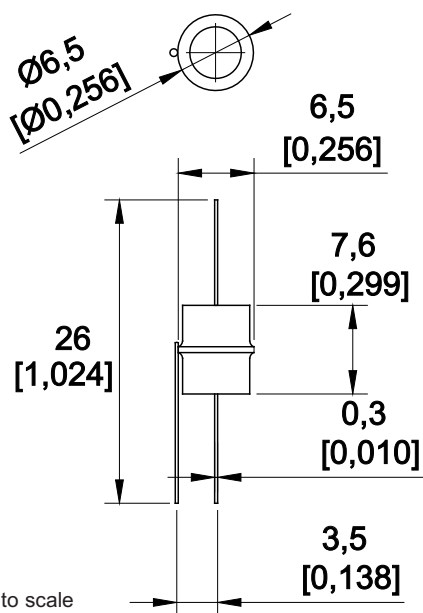

Drawings not to scale
 All dimensions in mm nominal

SPECIFICATION

Contact Form / Style	Change-over break before make	
Switching Voltage	Max Volts AC	60
Switching Current	Max Amps	0.2
Switching Capacity	Max VA	3
Contact Resistance	Max Ohms	10
Differential Angle	Max degrees	35
Operating Temperature	Celsius	-37° - 100°
Storage Temperature	Celsius	-40° - 125°
Case Material	Steel Gold plated	

Applications Include

- Low power tilt safety.
- Consumer tilt applications
- Alarm system switch.
- Tilt light control.

Features/Options

- Hermetically sealed.
- Inert gas filled

Rev. No.

2

Revision Note

Datasheet redesign

Date

05-03-12

Signature

ML

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone : (1)973 777 6900

www.comus-intl.com

Fax: (1)973 777 8405