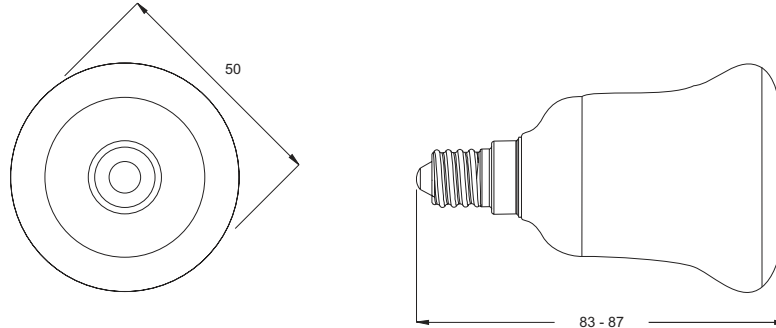


SYLVANIA**COMPACT
FLUORESCENT LAMP**MINI-LYNX
REFLECTOR
5W E14 10K**DIMENSIONS (mm)**

Cap Type: E14 - EN60061-1 sheet -7004-23

ELECTRICAL DATA¹

		<u>Nominal Value</u>	<u>Min.</u>	<u>Max.</u>
Lamp rated wattage	(W) :	5	4.3	5.5
Lamp operating voltage ac 50/60Hz (rms)	(V) :	230-240		
Lamp current ac 50/60Hz (rms)	(mA) :	35		

OPERATING CONDITIONS:

		<u>Nominal Value</u>	<u>Min.</u>	<u>Max.</u>
Cap Rim temperature	(°C) :			80
Lamp Ambient Temperature	(°C) :	25	-15	
Starting time at 25°C	(s) :			<2.0
Operating Position	:	Unrestricted		
Weight	(g) :	40		

LAMP LIFE²

Average life (IEC Test Cycle) (h) : 10000

PHOTOMETRIC DATA:

	colour no.	Luminous Flux nominal value (lm)	CRI (Class)	Colour Temp. (K)	ILCOS Code
Homelight Deluxe	827	165	1b	2700	FBT-5/27/1b-E14-50/85

Attention:

Lamps comply with EN 60 968 (Safety Requirements) and EN 60 969 (Performance Requirements) and CE Regulations.

¹Measured according to EN 60 969, at 50 Hz, lamp aged 100h²Life test according to EN 60 969

Issued by : Havells Sylvania UK Ltd
 Date : 01.01.2010
 Revision Date :

DATA SHEET

Specification No. : N6001
 Supersedes :
 Page : 1 of 1

HAVELLS SYLVANIA reserves the right to change data and specification without notice.
 Data for guidance only.