


B 261709 PC-V0-G 7024



Bocube
Enclosures, polycarbonate UL 94 V0, crystal-clear lid
Order no.: 96026334

Colour	Graphite grey
Colour of enclosure group	Graphite grey, similar to RAL 7024; light grey, similar to RAL 7035; special colours on request
Protection class	IP 66/IP 67 DIN EN 60529
Enclosure material	ABS or PC UL 94 V0 (material is suitable for outdoor use; f1-listing according to UL 746C), foamed seal; for details please see Technical Information Scope of delivery: Lid and base, hinged quick-release catches

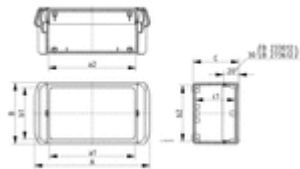

A	271 mm
B	170 mm
C	90 mm
a1	232 mm
a2	234,1 mm
b1	158 mm
b2	163,1 mm
c1	81,5 mm

Technical drawings	Catalogue drawing in DXF format: 96026334_B-261709-PC-V0-G-7024.dxf (3.9 MB) Catalogue drawing in PDF format: 96026334_B-261709-PC-V0-G-7024.pdf (252 KB) 3D product data in STEP format: Registration necessary Basic drawing for processing work: 96026334_B-261709-PC-V0-G-7024-G.dxf (3.2 MB)
Chapter download	Bocube_GB.pdf (459 KB) Highlights_Bocube.pdf (3.8 MB)

Accessories



Hinged quick-release catches (Set), polycarbonate UL 94 V0 or ABS

- 96310303 [B SC 17 PC-V0](#) For B 2617.. Traffic yellow
[1023](#)
- 96310305 [B SC 17 PC-V0](#) For B 2617.. Light grey
[7035](#)
- 96310304 [B SC 17 PC-V0](#) For B 2617.. Graphite grey
[7024](#)
- 96310309 [B SC 17 PC-V0](#) For B 2617.. Mint green
[6029](#)
- 96310302 [B SC 17 PC-V0](#) For B 2617.. Ultramarine blue
[5002](#)
- 96310300 [B SC 17 PC-V0](#) For B 2617.. Flame red
[3000](#)



Hand-operated hinged catch (set), polycarbonate UL 94 V0 or ABS

- 96910303 [B SC HB 17](#) For B 2617.. Traffic yellow
[PC-V0 1023](#)
- 96910305** [B SC HB 17](#) For B 2617.. Light grey
[PC-V0 7035](#)
- 96910304** [B SC HB 17](#) For B 2617.. Graphite grey
[PC-V0 7024](#)
- 96910309 [B SC HB 17](#) For B 2617.. Mint green
[PC-V0 6029](#)
- 96910302 [B SC HB 17](#) For B 2617.. Ultramarine blue
[PC-V0 5002](#)
- 96910300 [B SC HB 17](#) For B 2617.. Flame red
[PC-V0 3000](#)



Wall brackets

- 96510004 [B WL 7024](#) For B 08... - B 26... Graphite grey
- 96510005 [B WL 7035](#) For B 08... - B 26... Light grey




Mounting panels, laminated paper, 2 mm

- 96606300 [B M 2617](#) For B 2617..



Front panels, 2 mm, natural-coloured anodised aluminium

- 96706300 [B FP 2617](#) For B 2617.., front panel thickness 2.5 mm

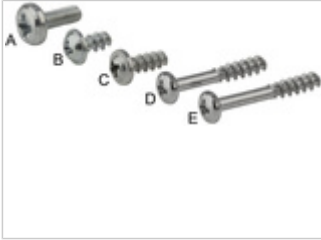

Sets of screws

- 96700000 [B FP-SHR](#) A (for fixing front panels)
- 96600010 [B M-SHR](#) C (for fixing mounting panels B M 1008-2736)
- 96300000 [B SHR](#) D (for optional screwing of enclosures B 0808 - 2617)



Distance bolts

- 96758000 [DIBLZ AK](#) ND = 2.4 - 2.6, for B...09
[30x5/IM3/58](#)
- 96756000 [DIBLZ AK](#) ND = 2.4-2.6, for B...09 if a mounting plate is used
[30x7/IM3/56](#)



Blanking plugs to determine the hinge side

- 96410004 [B VS 7024](#) Graphite grey
- 96410005 [B VS 7035](#) Light grey
- 96410000 [B VS 3000](#) Flame red



DIN rails DIN EN 60715 TH 15

- 22152301 [TS 15](#) For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)



DIN rails DIN EN 60715 G 32

- 22322301 [TS 32](#) For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)



DIN rails DIN EN 60715 TH 35

- 22352301 [TS 35](#) For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)

* = Available on request