





Datasheet

New 5.0mm Rising Clamp TB 25A 3 Way

RS Stock 874-5427



Dimensions: (mm)

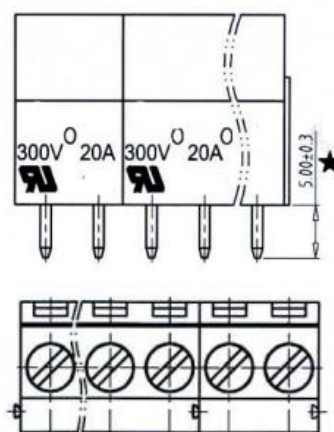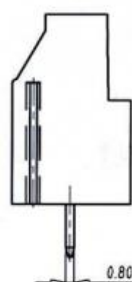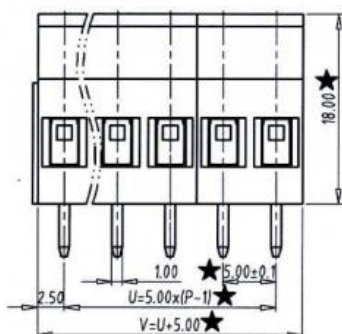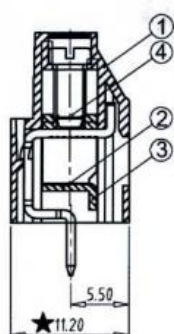

Specifications

- Rated Voltage: 300V 8A
- Insulation Resistance: 500ΩM or more at DC500V
- Withstanding Voltage: AC 2000V/1 min
- Temperature Range: -40°C ~ +105°C
- Screw Torque: 0.4N.m
- Suitable Electric Wire: 12-24AWG (UL) 0.34-2.5mm² (VDE)
- RoHS Compliance
- Stripping Length: 7-8mm

Materials

- Housing: PA66 / UL94V-0
- Block: Steel
- Solder pin: Copper
- Screw: Steel

DIM P	2	3	4	5	6	7	8	9	10	11	12	13											
V	10	15	20	25	30	35	40	45	50	55	60	65											
U	5	10	15	20	25	30	35	40	45	50	55	60											
DIM P	14	15	16	17	18	19	20	21	22	23	24												
V	70	75	80	85	90	95	100	105	110	115	120												
U	65	70	75	80	85	90	95	100	105	110	115												
Total Pitch Tolerances in mm									Nominal dimension range in mm									$\perp$		$\equiv$	$-$		$//$
over	over	over	over	over	over	over	over	over	over	over	over	over	over	over	over	over	over	over	over		over	over	over
0	30	53	70	90	115	150	200	250	0	30	53	70	90	115	150	200	250	0	over		0	100	over
to	to	to	to	to	to	to	to	to	to	to	to	to	to	to	to	to	to	to	10	all	to	to	150
30	53	70	90	115	150	200	250	320	30	53	70	90	115	150	200	250	320	10			to	to	
± 0.18	± 0.20	± 0.25	± 0.3	± 0.35	± 0.44	± 0.55	± 0.70	± 0.75	± 0.20	± 0.25	± 0.30	± 0.35	± 0.44	± 0.55	± 0.70	± 0.80	± 0.90	0.2	0.3	0.3	0.2	0.3	0.5