




Electrical Commercial and Industrial

- Products
- Documentation & Literature
- News & Tradeshow
- Support

United States > All 3M Products > Market Segments > Electronics, Electrical, and Communications > Electrical Products > Electrical Commercial and Industrial > Products > _____

3M™ Scotchlok™ Male Disconnect Nylon Insulated, 100/bottle, MNG14-250DMX

3M ID 80611458235 UPC# 00051128586785 3M Product Number MNG14-250DMX

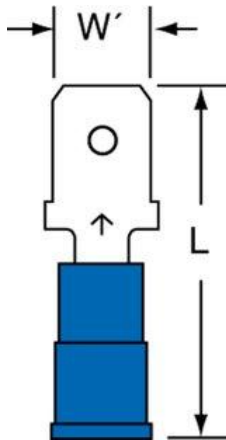

Male Disconnect Nylon Insulated, 100/bottle, MNG14-250DMX

- Overview
- Documentation

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.085 Inch
Barrel Style	Insulation Grip
Brand	Scotchlok
Conductor Sizes	16 - 14 AWG
CSA File Number	LR22190
Fastener Orientation	Male
Insulation Material	Nylon
Length (L)	0.94 Inch
Male Tab Width (W')	0.250 Inch
Maximum Insulation Outer Diameter	0.170 Inch
Packaging	100 per bottle
Pad Width	0.25 Inch
Terminal Style	Standard
Terminal Type	Disconnect
Thickness	0.032 Inch
UL File Number	E70512