

## TOLEDO BALL FROSTED 250LM B22 SL

0026953



### Range features

### PRODUCT OVERVIEW

Ordering number	0026953
Technology	LED
Light colour	Homelight
Energy class	A+
Average life (Rated) (h)	25000
Lamp shape	Ball
Lamp finish	Frosted
Dimmable	No
Cap/Base	B22
Type	ToLEDo Ball
EAN code	5410288269535
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Efficacy (Rated) (lm/w)	63
Watt (Nominal) (W)	4
Equivalent watt (W)	25
Voltage (V)	220-240

## TOLEDO BALL FROSTED 250LM B22 SL

0026953

### DATA TABLE

#### General data

Ordering number	0026953
Dry applications use only	Yes
Technology	LED
Average life (Rated) (h)	25000
Average life (Nominal) (h)	25000
Energy saving lamp	Yes
Energy class	A+
Lamp shape	Ball
Lamp finish	Frosted
Dimmable	No
Cap/Base	B22
Type	ToLEDo Ball
EAN code	5410288269535
Product name	TOLEDO BALL FROSTED 250LM B22 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	50000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	1
Optimal operating condition (°C)	25

#### Optical data

Light colour	Homelight
CRI (Ra)	80
Suitable for accent lighting	No
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	250
Adjustable chromaticity	No

## TOLEDO BALL FROSTED 250LM B22 SL

0026953

### Electrical data

<b>kWh per 1000 hours burning time</b>	4
<b>Efficacy (Rated) (lm/w)</b>	63
<b>Watt (Rated) (W)</b>	4
<b>Watt (Nominal) (W)</b>	4
<b>Equivalent watt (W)</b>	25
<b>Voltage (V)</b>	220-240
<b>Lamp power factor</b>	0.7

### Physical data


<b>Weight (kg)</b>	0.05
<b>Lamp Length (mm) - C/L</b>	78
<b>Max. Lamp Diameter (mm) - D</b>	45
<b>Lamp dimension equal to filament lamp equivalent</b>	Yes
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	10.20 x 4.80 x 4.80
<b>Inner package dimensions (L x W x H) (cm)</b>	15.50 x 10.50 x 11.00
<b>Inner package net weight (kg)</b>	0.27
<b>Outer package dimensions (L x W x H) (cm)</b>	55.00 x 32.60 x 13.00

## TOLEDO BALL FROSTED 250LM B22 SL

0026953

### TECHNICAL DRAWINGS

---

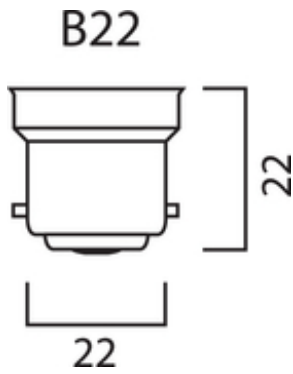

### ENERGY LABEL

---

□