



Datasheet

Stock No: 748-2323

ENGLISH

RS Pro Red/Brown Equipment Wire, 0.22 mm² CSA, 1000 V 24 AWG, 100m



BS 4808

Cable Construction

Conductor

square(mm²)

Construction

Standard Dia.(mm)

Insulation

Thickness

Insulation Dia.(±0.1mm)

Tinned Copper

0.22

T0.20±0.008×7


0.60

PVC

0.3

1.20

Design

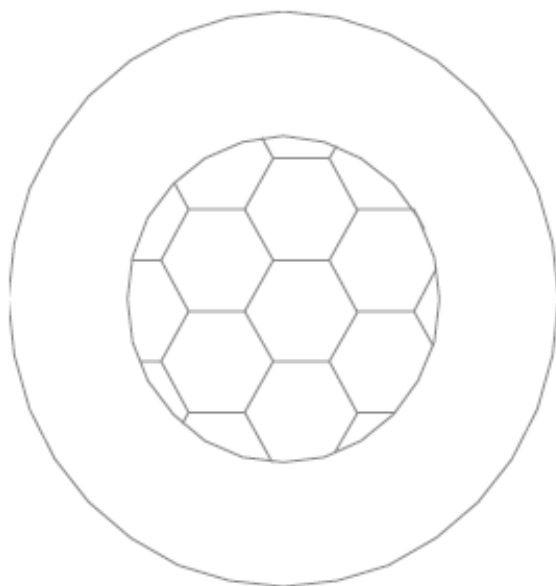

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<86.2
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1000