

Housing - HC-B 24-KMQ-N-O1PG29 - 1460251

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B24 coupling housing, with double locking latch, height: 70.5 mm, with 1 x Pg29 gland, straight cable outlet



Key commercial data

| | |
|--------------------------------------|--|
| Packing unit | 10 pc |
| GTIN |  4 046356 696197 |
| Weight per Piece (excluding packing) | 22.22 g |
| Custom tariff number | 85389099 |
| Country of origin | Germany |

Technical data

Dimensions

| | |
|--------|---------|
| Height | 70.5 mm |
| Width | 43 mm |
| Length | 120 mm |

Ambient conditions

| | |
|--------------------------------------|-------------------|
| Degree of protection of housing (IP) | IP65 |
| Ambient temperature (operation) | -40 °C ... 125 °C |

General

| | |
|------------------------------|--|
| Note | For contact inserts HC-B24, BB46, BBB64, D64, DD108, M |
| Type | B24 |
| Housing type | Coupling housings |
| Locking type | With double locking latch |
| No. of cable outlets | 1 |
| Cable exit | Straight |
| Screw connection | none |
| Type of the screw connection | 1x Pg29 |
| Housing material | Aluminum die-cast |

Housing - HC-B 24-KMQ-N-O1PG29 - 1460251

Technical data

General

| | |
|------------------------------|-----------------------------|
| Housing surface material | Powder-coated, gray |
| Seal material | NBR |
| Material lock | Stainless steel, handle: PA |
| Material grip body interlock | PA |

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 27140816 |
| eCl@ss 4.1 | 27140816 |
| eCl@ss 5.0 | 27143424 |
| eCl@ss 5.1 | 27143424 |
| eCl@ss 6.0 | 27143424 |
| eCl@ss 7.0 | 27440209 |
| eCl@ss 8.0 | 27440202 |

ETIM

| | |
|----------|----------|
| ETIM 3.0 | EC000437 |
| ETIM 4.0 | EC000437 |
| ETIM 5.0 | EC000437 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 31261502 |
| UNSPSC 7.0901 | 31261502 |
| UNSPSC 11 | 31261502 |
| UNSPSC 12.01 | 31261502 |
| UNSPSC 13.2 | 31261502 |

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approvals submitted

Housing - HC-B 24-KMQ-N-O1PG29 - 1460251

Approvals

Approval details

| |
|-----|
| EAC |
|-----|

Accessories

Accessories

Full screw connection

Cable gland - G-INS-PG29-M68N-PNES-GY - 1411146



Cable gland, Cable gland material: Polyamide, External cable diameter 18 mm ... 25 mm, Shielding: No, Connecting thread: Pg29, Color: silver grey

Cable gland - G-INS-PG29-M68N-NNES-S - 1411176



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 18 mm ... 25 mm, Shielding: No, Connecting thread: Pg29, Color: silver

Cable gland - G-INSEC-PG29-M68N-NNES-S - 1411201



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 18 mm ... 25 mm, Shielding: Yes, Connecting thread: Pg29, Color: silver

Plug for cable screw gland

Filler plugs - HC-BS-PG29 - 1674532




Filler plugs, for Pg screw connections, type Pg29

Drawings

Housing - HC-B 24-KMQ-N-O1PG29 - 1460251

Dimensioned drawing

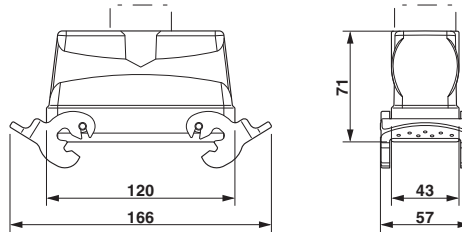

Dimensional drawing

Phoenix Contact 2015 © - all rights reserved
<http://www.phoenixcontact.com>