




Tapered roller bearings, single row

| Principal dimensions |       |        | Basic load ratings |              | Speed ratings   | Limiting speed | Designation            |
|----------------------|-------|--------|--------------------|--------------|-----------------|----------------|------------------------|
| d                    | D     | T      | dynamic<br>C       | static<br>C0 | Reference speed |                | * SKF Explorer bearing |
| mm                   |       |        | kN                 |              | r/min           |                | -                      |
| <b>28,575</b>        | 57,15 | 19,845 | 45,7               | 51           | 9000            | 13000          | 1988/1922/Q            |

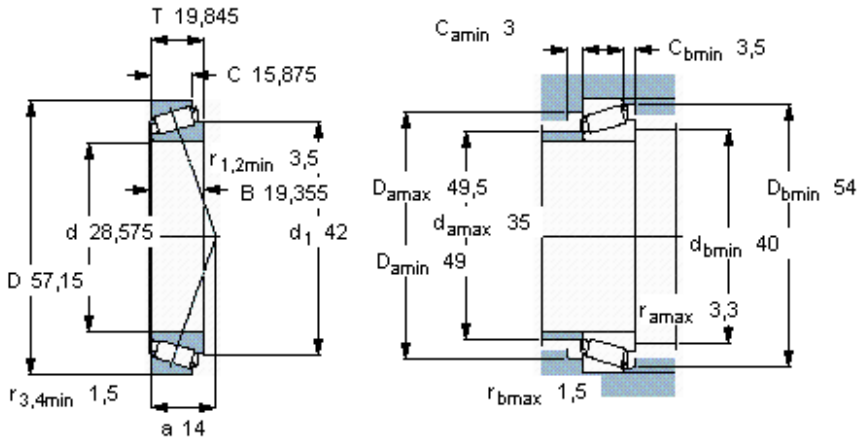

**Calculation factors**

e 0,33  
Y 1,8  
 $Y_0$  1