

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [83424-9062](#)
Status: **Active**
Overview: Commercial Micro-D High-Density Connectors
Description: Commercial Micro-D Cable Assembly, 25 CMD-to-25 Pin D-Subminiature (Female-to-Male), 1.83m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	83424
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Commercial Micro-D-to-D-Sub
Overview	Commercial Micro-D High-Density Connectors
Product Name	Commercial Micro-D, D-Sub
UPC	822350652148

Physical

Cable Length	1.83m
Circuits (Loaded)	25
Gender	Male-Female
Lock to Mating Part	Yes
Material - Plating Termination	Tin
Net Weight	2.180/g
Packaging Type	Bag
Plating min - Mating	0.127µm
Plating min - Termination	1.270µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	PVC


Electrical

Current - Maximum per Contact	1A
Shield Type	AL Foil
Shielded	Yes

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-83424-060
---------------	--------------

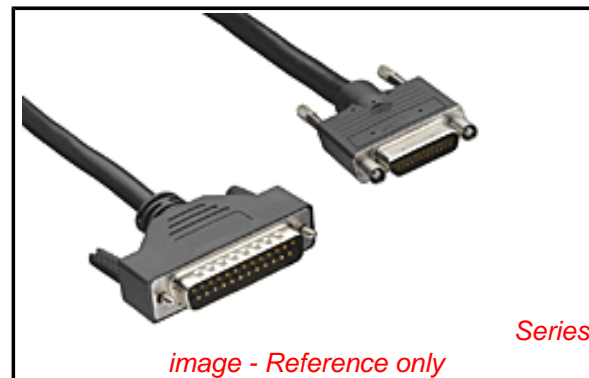

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[83424Series](#)

Mates With

Ulti-Mate™ Commercial Micro D, [83612](#) , [83619](#)