 



70-205 kg

Industrial Castors Series 3470

Housing made of pressed steel, zinc-chromatised, double ball bearing swivel head, dustguard, wheel axle with nut


 




 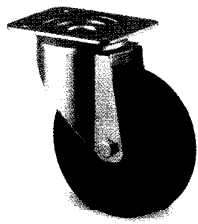



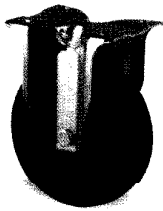
Wheel: PVR
Wheel centre: Polypropylene
Tread: solid rubber, black, without threadguards, roller bearing



3470 PVR 125 P62








Swivel Castor


								
	mm	mm	mm	mm	mm	mm	mm	kg
3470 PVR 080 P62	080	35	105 x 85	80/77 x 60	9	44,5	108	70
3470 PVR 100 P62	100	35	105 x 85	80/77 x 60	9	41	128	75
3470 PVR 125 P62	125	37	105 x 85	80/77 x 60	9	40	155	100
3470 PVR 125 P63	125	37	137 x 105	105 x 80/75	11	55	161	100
3470 PVR 160 P63*	160	40	137 x 105	105 x 80/75	11	55	200	135
3470 PVR 200 P63*	200	50	137 x 105	105 x 80/75	11	55	240	205



3478 PVR 125 P62


 




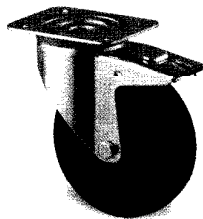

Fixed Castor

							
	mm	mm	mm	mm	mm	mm	kg
3478 PVR 080 P62	080	35	103 x 85	80/77 x 60	9	108	70
3478 PVR 100 P62	100	35	103 x 85	80/77 x 60	9	128	75
3478 PVR 125 P62	125	37	103 x 85	80/77 x 60	9	155	100
3478 PVR 125 P63	125	37	137 x 115	105 x 80/75	11	161	100
3478 PVR 160 P63	160	40	137 x 115	105 x 80/75	11	200	135
3478 PVR 200 P63	200	50	137 x 115	105 x 80/75	11	240	205



3477 PVR 125 P62


Swivel Castor with total lock

								
	mm	mm	mm	mm	mm	mm	mm	kg
3477 PVR 080 P62	080	35	105 x 85	80/77 x 60	9	44,5	108	70
3477 PVR 100 P62	100	35	105 x 85	80/77 x 60	9	41	128	75
3477 PVR 125 P62	125	37	105 x 85	80/77 x 60	9	40	155	100
3477 PVR 125 P63	125	37	137 x 105	105 x 80/75	11	55	161	100
3477 PVR 160 P63	160	40	137 x 105	105 x 80/75	11	55	200	135
3477 PVR 200 P63	200	50	137 x 105	105 x 80/75	11	55	240	205


* These castors are mounted and shipped with yellow chromated plates.

Directional locking castors are available in all sizes, see page 180.


Fixing Plates:

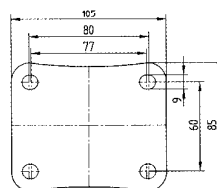


Swivel Castor P62 105x85

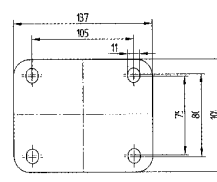

Swivel Castor P63-137x105

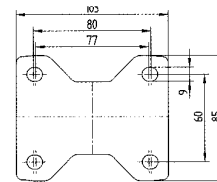

Fixed Castor P62-103x85

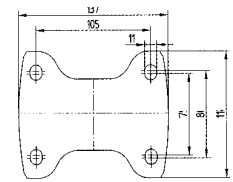

Fixed Castor P63-137x115