

Product

TK PC 99-6-m



Empty enclosure - Industrial Quality -, box and cover:
glass fibre reinforced polycarbonate, grey, similar to RAL
7035

with metric knockouts

Article: TK PC 99-6-m

Technical Data

Dimensions:

interior height: 45 mm

material:


Base: Polycarbonate, glass-fibre reinforced, grey simila
Cover: Polycarbonate, glass-fibre reinforced, grey simila
Sealing: Polyurethane
Cover screw: Polyamide 6, fiber-glass reinforced

Properties:

Ingress protection: IP66 - acc. EN 60529 / DIN VDE 0470-1
Ambient temperature (max.): 80 °C
Ambient temperature (24 h): 60 °C
Max. rel. humidity at 40° C: 50%
Max. rel. humidity at 25° C (short Therm): {100%}
Rated insulation voltage AC: 690V
Impact resistance: {IK08 nach DIN EN 5012 / VDE 0470 Teil 100 }
Protection class: II - isolate protection acc. VDE 0106 Protective insulation as per VDE 0106
Halogen-free: √
Heavy metals-free: √
PVC-free: √

Silicone-free:	√
UV resistance:	√
Weatherproof:	√
Combustion behaviour to UL:	5VA nach UL 50 / UL 746C
Combustion behaviour to UL:	{V-2 nach UL 94}
Combustion behaviour to VDE:	960°C acc. VDE 0471/ EN 60695
Fitted for outdoor application:	√
Knockouts:	√

Drawing

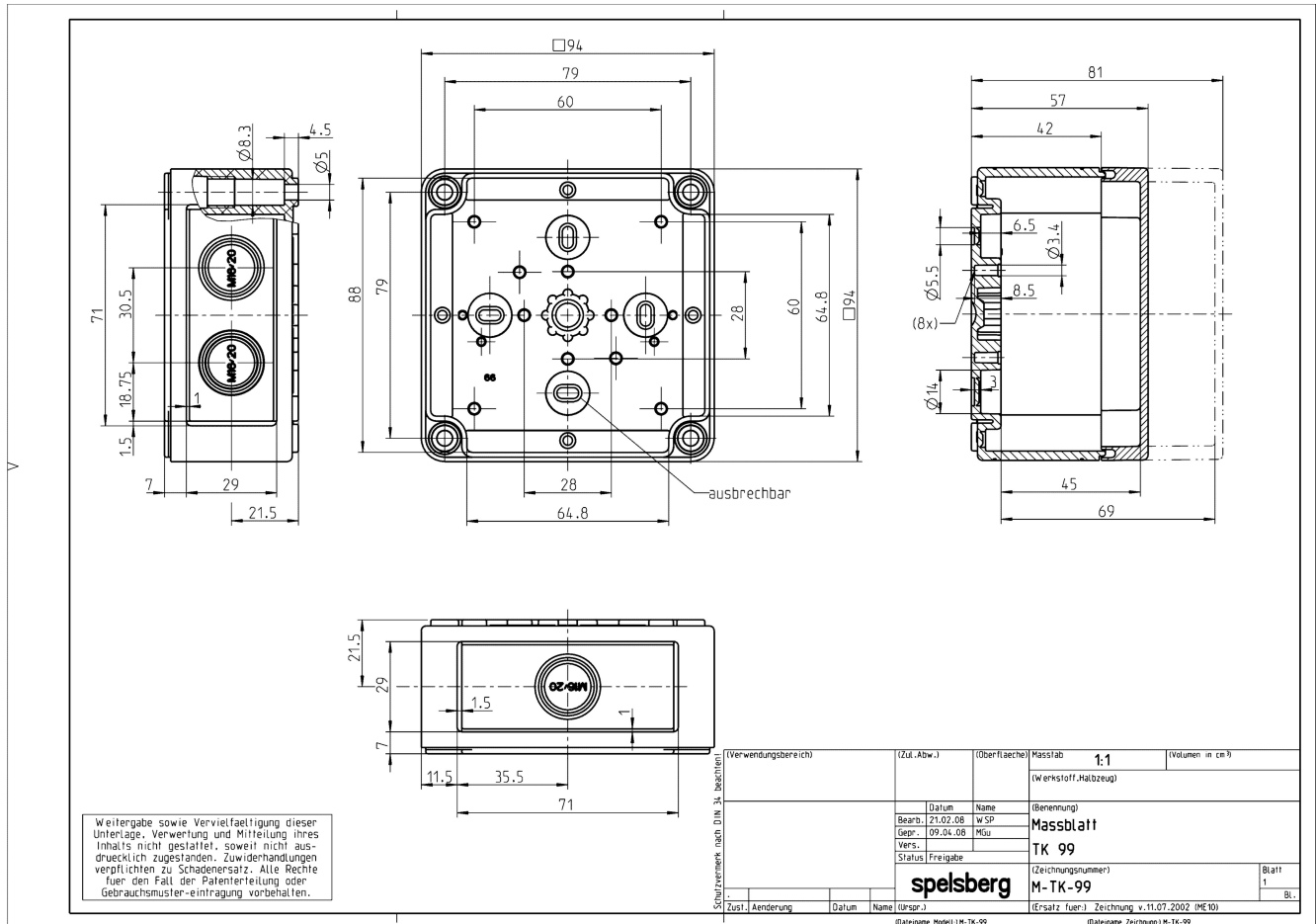

Manufacturer Günther Spelsberg GmbH + Co. KG
 Im Gewerbepark 1
 58579 Schalksmühle
 +49 (0)2355/892-0
 +49 (0)2355/892-299
 www.spelsberg.de