


Spherical roller bearings, cylindrical and tapered bore

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
50	90	28	104	108	11,8	-	1900	0,70	BS2-2210-2CS/VT143 *

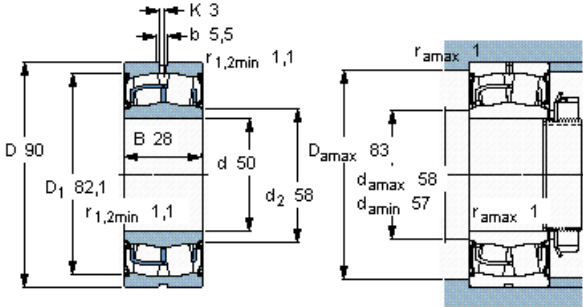

Calculation factors

- e 0,24
- Y_1 2,8
- Y_2 4,2
- Y_0 2,8