


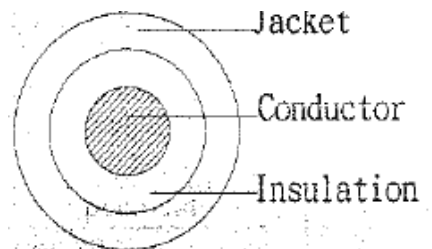

Product Name:	UL1385 24AWG
Product Discription:	UL1385 24AWG
Specification No.:	SPEC-UL1385-24AWG
Customer's Name:	

Description					Construction										
Rated Voltage:		No voltage rating			Conductor		Stranded Tinned Copper								
Rated Temperature:		125℃			Size(AWG)		24								
Reference Standard:		UL758			Construction(±0.004mm)		11/0.16								
Cross Section					Stranded Dia.(mm)Ref.		0.61								
					Insulation Material		XL-PE		Jackert Material		XL-PVDF				
					Insulation Color		White		Jacket Color		Any color				
					Ave Thickness(mm)		0.15		Ave Thickness(mm)		0.10				
					Min Thickness(mm)		0.12		Min Thickness(mm)		0.08				
					Insulation Dia.(±0.10mm)		0.90		Jacket Dia.(±0.10mm)		1.10				
Marking					Remark:										
No cable marking					8918741 Red		8918744 Blue		8918763 Grey		8918766 Violet				
					8918738 Black		8918748 White		8918750 Yellow						
					8918732 Brown		8918757 Green		8918754 Orange						
Applications					Characteristics							Customer Approve			
Internal wiring of electronic equipment.					Test Item				Standard Value				Seal & Stamp		
					Test Material				XLPE and XLPVDF(ROHS)						
					Insulation resistance(20℃ MΩ/KM				0.75						
					Vol. Tesr(AC.V.60S) (V)				500						
					Flammability Test				Horizontal flame						
Revisions					Max.DC Resistance(20℃ Ω/km)				94.2(MAX)				Signature: Date:		
Version		Description		Drawn by		Approved by		Date							
0		New document issue		YanBin		Jason		10/08/2015							