

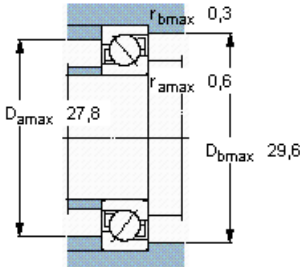


Angular contact ball bearings, single row

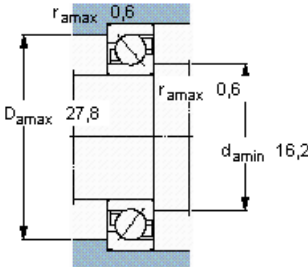

Principal dimensions			Basic load ratings		Fatigue load limit	Speed ratings		Mass	Designation
d	D	B	dynamic	static	P_u	Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
12	32	10	7,61	3,8	0,16	26000	26000	0,036	7201 BEP

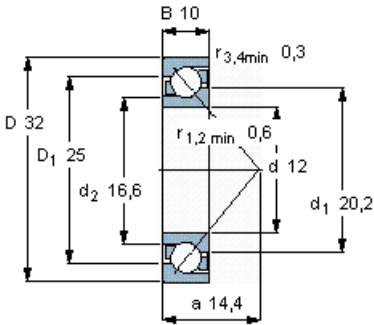

Calculation factors
 k_r 0,095
 k_a 1,4
 e 1,14
 X 0,35
 Y 0,57
 Y_0 0,26