


Unique stand design allows you to simultaneously slide the panel toward you while tilting it up to 60°.



Back view

Connectors

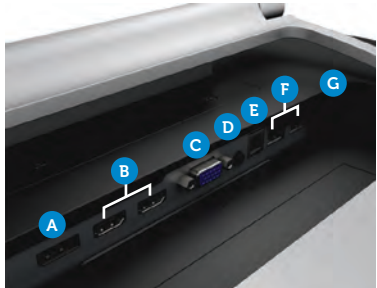

- A

DisplayPort
- B

HDMI
- C

VGA
- D

Audio out
- E

USB upstream
- F

USB downstream
- G

Security cable slot
- H

USB downstream



What's in the box?

Monitor with stand, power cable (varies by country), power adapter, HDMI cable, USB 3.0 upstream cable, screen cleaning cloth, Velcro strap, Quick Setup Guide, Drivers and Documentation media, Product and Safety Information Guide.



Dell 23 Monitor — Touch | P2314T (23", 58.42 cm VIS)


Display	
Model number	P2314T
Viewable image size (diagonal)	58.42 cm (23 inches)
Active display area	
Horizontal	509.184 mm (20.05 inches)
Vertical	286.416 mm (11.28 inches)
Maximum resolution	Full HD 1920 x 1080 at 60 Hz
Aspect ratio	16:9
Pixel pitch	0.2652 (H) mm x 0.2652 (V) mm
Brightness (typical)	270 cd/m²
Color gamut (typical)	83% ⁶
Color depth	16.77 million colors
Contrast ratio (typical)	1,000:1 (typical)
Dynamic contrast ratio (typical)	8 million:1 (DCR)
Viewing angle (typical) (vertical/horizontal)	178°/178°
Response time (typical)	8 ms gray to gray with overdrive
Panel technology, surface	In-plane switching / Plane to line switching, glossy
Backlight	LED
Connectivity	
Connectors	VGA, DisplayPort, 2x HDMI (including MHL), 2x USB 3.0 ⁷ , 2x USB 2.0
Features	
Stand	Tilts up to 60°
Security	Security lock slot (security lock not included)
VESA mounting support (wall mount sold separately)	Dell Quick Release mount, 100 mm x 100 mm
Power	
AC input voltage/frequency/current	100 to 240 VAC/50 or 60 Hz ± 3 Hz/1.5 A (maximum)
Power consumption (normal operation, typical)	17 W
Power consumption (active-off mode)	<0.5 W
Dimensions (with stand)	
Height (compressed ~ extended)	412.7 mm (16.25 inches) ~ 216.4 mm (8.52 inches)
Width	569.9 mm (22.44 inches)
Depth (compressed ~ extended)	80.9 mm (3.19 inches) ~ 421.3 mm (16.59 inches)
Weight	
Weight (panel only – no stand)	4.82 kg (10.60 lbs)
Weight (with stand)	7.10 kg (15.62 lbs)
Shipping weight	8.98 kg (19.76 lbs)
Environmental compliance	
ENERGY STAR®, EPEAT® Gold, TCO Certified Displays, China Energy Label, CEL, WEEE, ErP (EuP) Standards, Korea E-Standby	
Standard service plan	
• 3 years Advanced Exchange Service ⁵ & Limited Hardware Warranty ⁴ • Premium Panel Guarantee ³	

*DisplayPort, VGA, and MHL cables not included.
**Registered in US and Canada only.
¹ Microsoft, Windows, Windows Vista and the Windows logo are trademarks of Microsoft group of companies.
² MHL connectivity works with smartphones and tablets with MHL out and that are in compliance with MHL standards.
³ Even if only one bright pixel is found on our select range of monitors, a free panel exchange is guaranteed during the Limited Hardware Warranty period (see pixel panel info located on dell.com web page for complete details): <http://support.dell.com/support/topics/global.aspx/support/kcs/document?docid=414288>
⁴ For a copy of the Limited Hardware Warranty, write to Dell USA LP, Attn: Warranties, One Dell Way, Round Rock, TX 78682 or see dell.com/warranty.
⁵ Advanced Exchange Service: Replacement part/unit dispatched, if needed, following completion of phone/online diagnosis. Fee charged for failure to return defective unit. Availability varies. Other conditions apply.
⁶ Color gamut (typical) is based on CIE1976 (83%) and CIE1931 (72%) test standards.
⁷ USB 3.0 does not support graphics output. USB 3.0 rate of data transfer can only be achieved with a computer that supports USB 3.0

Product availability varies by country. Please contact your Dell representative for more information.
Based on Dell document Ad#A13001708 dell.com/monitors

Dell 23 Monitor — Touch
Model P2314T

23" monitor

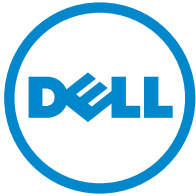

A boldly reimagined monitor experience —
the Dell 23 Touch Monitor can meet your
needs and budget



Dell 23 Monitor — Touch | P2314T
(23", 58.42 cm VIS)

Dell 23 Monitor — Touch Model P2314T

23" monitor

The Dell 23 Touch Monitor

Bringing a boldly re-imagined monitor experience to you with:

- Natural and intuitive 10-point multi-touch
- Enhanced and extensive connectivity with MHL, DisplayPort, HDMI, VGA, and USB ports
- Amazing screen experience with Full HD resolution and ultra-wide viewing angle
- Innovative design with sleek, edge-to-edge glass and unique stand design
- An affordable touch monitor solution
- Unmatched reliability



The Dell 23 Touch Monitor | P2314T (23", 58.42 cm VIS) offers you:

An engaging touch experience

- Natural, direct and intuitive, the touch interface of the Dell 23 Monitor offers you a fast and easy way to use your applications. Tap, slide, swipe, turn, pinch and stretch images on the screen with your fingers thanks to the Dell 23 Monitor's 10-point multi-touch capability — it's that simple and intuitive when used with Windows® 8¹.
 - Connect a USB cable from your PC to the monitor's USB upstream port to enable touch, and use either an HDMI, DisplayPort* or VGA* cable to project images onscreen.
- Enjoy amazing screen clarity and pin sharp details with the 16:9 Full High Definition 1920 x 1080 (max) resolution, and high 8 million:1 dynamic contrast ratio.
- View images on the monitor from virtually any angle and still enjoy the same superb visual experience with the 178°/178° ultra-wide viewing angle.
- Sleek and stylish edge-to-edge glass gives the Dell 23 Monitor a clean finish that boasts of fine craftsmanship, enhancing your overall viewing experience.

Seamless connectivity to smart phones, tablets, and other devices for great usability and convenience

- Easily project content from your smart phone or tablet directly onscreen via HDMI (including MHL*²); you can even transform your touch monitor into a thin client solution with the Dell Wyse personal cloud stick.
- Enjoy seamless connectivity with various devices via a versatile array of VGA, USB, DisplayPort, and HDMI ports.
- Experience additional convenience with stand viewing options.
 - Easily slide the monitor toward yourself to touch and type and tilt it up to 60° to suit your viewing needs.
 - VESA compatibility — Enjoy the flexibility of mounting the panel on the wall, or attaching it to the Dell Single Monitor Arm via the VESA adaptor plate. (Wall mount kit and Dell Single Monitor Arm both sold separately).

An affordable touch monitor with unmatched reliability

- Choose a touch monitor that can meet your needs, from affordability to usability.
- Rest assured that Dell's Premium Panel Guarantee³ offers a free panel exchange in the event that you discover even one bright pixel during the Limited Hardware Warranty⁴ period.
- Enjoy peace of mind with Dell's Limited Hardware Warranty⁴ and Advanced Exchange Service⁵ to minimize your downtime.
- Minimize environmental impact with the Dell 23 Monitor which meets the latest regulatory and environmental standards like ENERGY STAR®, EPEAT® Gold and TCO Certified Displays.
- Control power consumption with power management features like PowerNap.

Perfect for:

- Connectivity to smart devices, easy access to information in the cloud, previewing touch applications on a larger screen.
- Movies, games, surfing the Internet and other multimedia entertainment.



Dell 23 Monitor — Touch | P2314T (23", 58.42 cm VIS)