



Datasheet



ENGLISH

Embedded Linear Power Supply Encapsulated, 240V ac Input, 12V dc Output, 6A, 72W

RS Stock 597-554



Dimensions (mm)

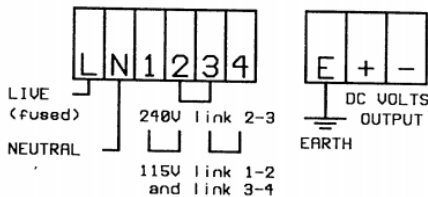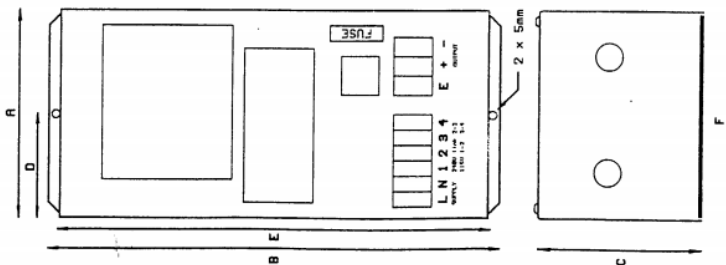

Specification

INPUT: 110/120 or 220/240 Vac
50/60 Hz Link selectable
Supplied set at 220/240

OUTPUT:	V dc	A dc	Fuse
PS1206	12	6	7.5
PS1212	12	12	15
PS2406	24	6	7.5
PS2412	24	12*	15
PS4806	48	6	7.5

* Derated to 10A after 1hr

Output fuse 1.25 x 0.25 QB

REGULATION: 20% typ

RIPPLE: 5% typ

TEMPERATURE: 0 to + 40C

Note: mains supply must be fused