



ENGLISH


## Datasheet

### 25 Way Ribbon Cable 359964



CONDUCTORS	28 AWG 7/36 Tinned Copper
INSULATION	.010" PVC
LAMINATE	.005" Clear PVC
COLOUR CODE	Brown, red, orange, yellow, green, blue, violet, grey, white, black & repeat
TEMPERATURE RATING	105°C
IMPEDANCE	105Ω
CAPACITANCE	13 pF/ft @ 1MHz
PROPAGATION DELAY	1.5 ns/ft

CURRENT RATING	1.3 A @ 10°C rise above ambient
VOLTAGE RATING	300 V
INSULATION RES	10 Ω - 10 ft minimum
APPROVALS	UL AWM style 20130
Above values calculated in the ground-signal configuration	

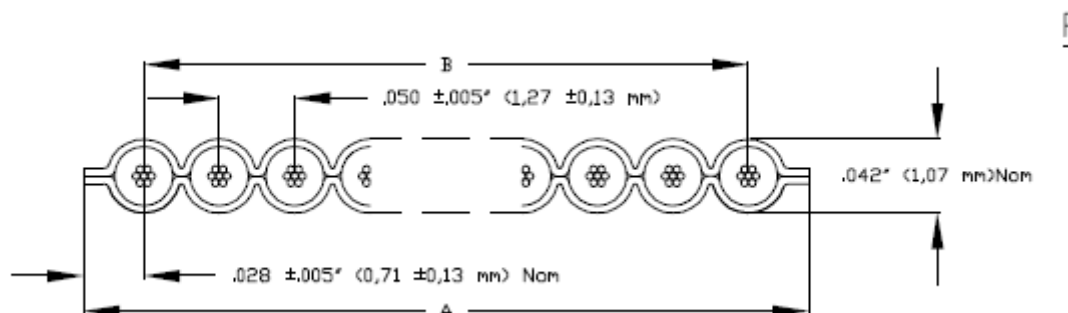

A Span 1.255" or 31,88mm

B Span 1.200±0.15" or 30,48±0,38mm