


EPIC® Rectangular Connectors




MC Series Plugs & Receptacles

4 CONTACT HE MODULES

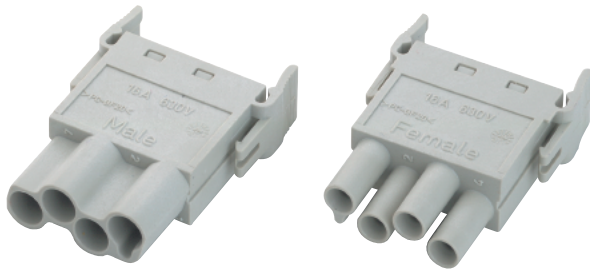

Rated Voltage:
630V


Rated Current:
25A

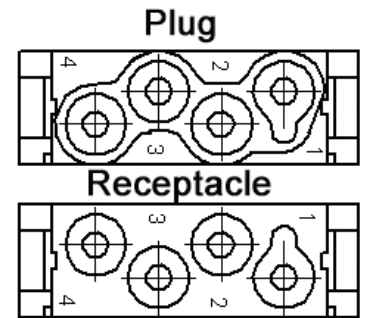

Contacts Sold Separately

Plug	Receptacle
10399000	10399100

MACHINE CONTACTS: DIAMETER 2.5 MM

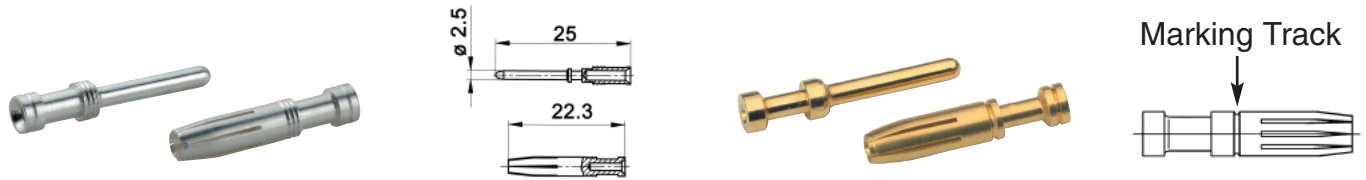

Bags of 100							
mm ²	AWG	Silver		Gold		Stripping Length (mm)	# of Marking Tracks
		Pin	Socket	Pin	Socket		
0.5	20	11190000	11195000	11192000	11197000	Pin=7.4, Socket =7.3	-
.75 - 1.0	18	11190100	11195100	11192100	11197100	Pin=7.4, Socket =7.3	1
1.5	16	11190200	11195200	11192200	11197200	Pin=7.4, Socket =7.3	2
2.5	14	11190300	11195300	-	-	Pin=7.4, Socket =7.3	3
4.0	12	11190400	11195400	-	-	Pin=7.4, Socket =7.3	-

Part number= 1 contact

CRIMP TOOLS



Crimp Tool
11147000



Crimp Dies
11147100



Locator
11147200



Removal Tool
11182500