


Dell 22 Monitor

Model E2214H

54.60 cm / 21.5" monitor

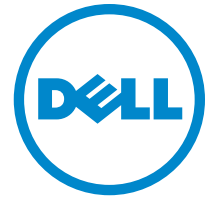

Reliable and efficient, offering essential features for home and business

The Dell 22 Monitor is your smart choice for essential productivity features, unmatched reliability, and energy-saving environment and regulatory compliance. In addition, the Dell 22 Monitor offers family entertainment features and the security of Dell's Limited Hardware Warranty¹ and Advanced Exchange Service².

The Dell 22 Monitor is perfect for:

- **Task workers for basic office productivity**
- **Educational institutions (computer labs, classrooms)**
- **Call centers, data entry centers, sales order input and administration**
- **Home use for Internet and shopping online**



Dell 22 Monitor | E2214H (54.60 cm, 21.5")



Dell 22 Monitor | E2214H (54.60 cm, 21.5")

The Dell 22 Monitor | E2214H (54.60 cm, 21.5" VIS) offers you:

Essential features for business productivity and home entertainment

- Get awesome screen clarity when you view applications and spreadsheets on-screen with the Full HD resolution and fast 5ms (typical) response time of the Dell 22 Monitor.
- Easily access peripherals and devices with the plug and play VGA and DVI-D ports.
- Adjust the monitor up to 5.5° forward or 22° backward to your preferred angle with the smooth tilt function.

Environmentally conscious and energy efficient

- For business
 - Help reduce your business' carbon footprint and environmental impact with the Dell 22 Monitor, which meets latest regulatory and environmental standards.
 - Experience the increased energy efficiency of the Dell 22 Monitor with low power consumption of 19W (typical).
- For home
 - Since the power-efficient Dell 22 Monitor meets the latest ENERGY STAR®, TCO Certified Displays, EPEAT® Gold**, and CEL requirements, be assured that it can help save you money.
- Manage power consumption wisely with PowerNap, a brightness dimming feature which, when enabled, puts the monitor into sleep mode when it's not in use.

Reliability you can count on

- For business
 - Benefit from Dell's quality monitoring and rigorous product development stages which help ensure reliability, avoid downtime and keep your workforce productive.
 - Plan transitions easily with Dell's stable product life cycles and worldwide product availability.
- For home
 - Enjoy seamless compatibility with Dell monitors and Dell systems and accessories.
 - Experience reliability thanks to Dell's rigorous product testing and high quality standards.
- Enjoy peace of mind with Dell's Limited Hardware Warranty¹ and Advanced Exchange Service².

Designed with essential features
for home and business



Maximum tilt 5.5° forward or 22° backward.

Connectors



Upgrade to P2214H⁵

In-plane switching panel technology,
DisplayPort connectivity

What's in the box?

Monitor, stand, VESA screw cover, power cable, drivers, documentation media, Quick Set Up Guide and Safety Information, VGA cable, DVI-D cable.

Dell recommends that customers dispose used computer hardware, including monitors, in an environmentally sound manner. Potential methods include reuse of parts or whole products and recycling of product, components and/or materials. For more information, please visit http://dell.com/recycling_programs and www.dell.com/environment



Dell 22 Monitor | E2214H (54.60 cm, 21.5" VIS)

Display

Model number	E2214H
Viewable image size (diagonal)	54.60 cm (21.5 inches)
Active display area	
Horizontal	476.6 mm (18.77 inches)
Vertical	268.1 mm (10.56 inches)
Maximum resolution	Full HD 1920 x 1080 at 60 Hz
Aspect ratio	16:9
Pixel pitch	0.248 mm
Brightness (typical)	250 cd/m ²
Color gamut (typical)	84% ³
Color depth	16.7 million colors
Contrast ratio (typical)	1000:1
Viewing angle (typical) (vertical/horizontal)	160°/ 170°
Response time (typical)	5 ms (black to white)
Panel technology	TN (active matrix – TFT LCD)
Backlight	LED

Connectivity

Connectors	VGA, DVI-D (HDCP)
Dell soundbar ⁴ (optional)	AC511
Remote asset management	Yes, via Dell Display Manager

Design features

Stand	Tilt only (Typical: 5° forward or 21° backward; Maximum: 5.5° forward or 22° backward)
VESA mounting support (wall mount kit sold separately)	100 mm x 100 mm
Security	Security lock slot and stand lock (security lock not included)

Power

AC input voltage/frequency/current	100 to 240 VAC/50 or 60 Hz ± 3 Hz/1.5 A (typical)
Power consumption	19W (typical)
Power consumption standby/sleep mode	<0.5 W

Dimensions (with stand)

Height	396.7 mm (15.62 inches)
Width	513.2 mm (20.20 inches)
Depth	165.5 mm (6.52 inches)

Weight

Weight (panel only – no stand)	2.70 kg (5.94 lb)
Weight (with stand)	3.80 kg (8.36 lb)
Shipping weight	5.20 kg (11.44 lb)

Standard service plan

- 3 years Advanced Exchange Service²
& Limited Hardware Warranty¹

Environmental compliance

ENERGY STAR®, TCO Certified Displays, EPEAT® Gold**, China Energy Label, WEEE, ErP (EuP) Standards, Korea E-Standby

*Registered in US and Canada only.

**EPEAT Gold registered in the U.S. EPEAT registration varies by country. See www.epeat.net for registration status by country.

¹ For a copy of the Limited Hardware Warranty, write Dell USA LP, Attn: Warranties, One Dell Way, Round Rock, TX 78682 or see dell.com/warranty.

² Advanced Exchange Service: Replacement part/unit dispatched, if needed, following completion of phone/online diagnosis.

Fee charged for failure to return defective unit. Availability varies. Other conditions apply.

³ Color gamut (typical) is based on CIE1976 (84%) and CIE1931 (72%) test standards.

⁴ Only compatible with AC511 soundbar. Launch date for soundbar varies across countries. Please check with your country sales representatives for more information.

⁵ Please check with your sales representative for availability of upgrade product.

Based on Ad # A13001968 dell.com/monitors

Product availability varies by country. Please contact your Dell representative for more information.