

## Cable sleeve - CES-STPG-GY-4X5 - 1410136

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Small, slotted cable sleeves suitable for four cables with a diameter of 4 ... 5 mm, material: SEBS



### Key commercial data

Packing unit	10 pc
GTIN	 4 046356 776288
Weight per Piece (excluding packing)	7.33 g
Custom tariff number	85472000
Country of origin	Poland

### Technical data

#### Dimensions

External cable diameter	4x 4 mm ... 5 mm
-------------------------	------------------

#### Ambient conditions

Degree of protection	IP54
	IP55 (when using a CES-B...-SFFS-PLBK sealing frame with screw locking)
Ambient temperature (operation)	-40 °C ... 80 °C (static)

#### General

Material	SEBS
Inflammability class according to UL 94	V0
Color	gray

### Classifications

#### eCl@ss

eCl@ss 4.0	27081002
eCl@ss 4.1	27081002

# Cable sleeve - CES-STPG-GY-4X5 - 1410136

## Classifications

### eCl@ss

eCl@ss 5.0	27081002
eCl@ss 5.1	27081002
eCl@ss 6.0	27081002
eCl@ss 7.0	27081002
eCl@ss 8.0	27081002

### ETIM

ETIM 3.0	EC000879
ETIM 4.0	EC002498
ETIM 5.0	EC000451

### UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708

## Approvals

### Approvals

---

Approvals

UL Recognized / cUL Recognized / cULus Recognized

---

Ex Approvals

---

Approvals submitted

---


### Approval details

UL Recognized
---------------

cUL Recognized
----------------


# Cable sleeve - CES-STPG-GY-4X5 - 1410136

## Approvals

cULus Recognized  US

## Drawings

Dimensioned drawing

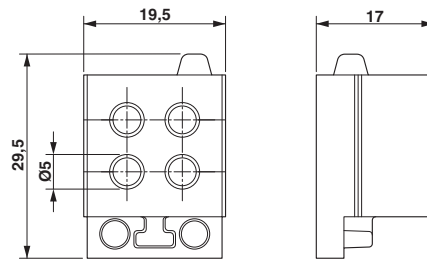

Dimensional drawing