

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [73101-0120](#)
Status: **Active**
Overview: [BNC RF Connectors](#)
Description: 75 Ohms, BNC Right-Angle PCB Bulkhead Jack Receptacle with Board Locks, Low Profile

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E107635

General

Product Family RF/Coax Connectors
 Series [73101](#)
 Comments Low Profile
 Overview [BNC RF Connectors](#)
 Product Name BNC
 Style PCB
 UPC 800753680296
 Wire/Cable Type N/A

Physical

Flammability 94V-2
 Gender Jack
 Keying to Mating Part None
 Net Weight 16.575/g
 Orientation Right Angle
 PCB Mounting Through Hole
 PCB Thickness - Recommended 3.20mm
 Packaging Type Tray
 Panel Mount Yes
 Panel Mount Method Bulkhead
 Reverse Polar No

Electrical

Impedance 75#


Solder Process Data

Duration at Max. Process Temperature (seconds) 5
 Lead-free Process Capability Wave Capable (TH only)
 Max. Cycles at Max. Process Temperature 1
 Process Temperature max. C 245

Material Info

Reference - Drawing Numbers

Sales Drawing SD-73101-0120

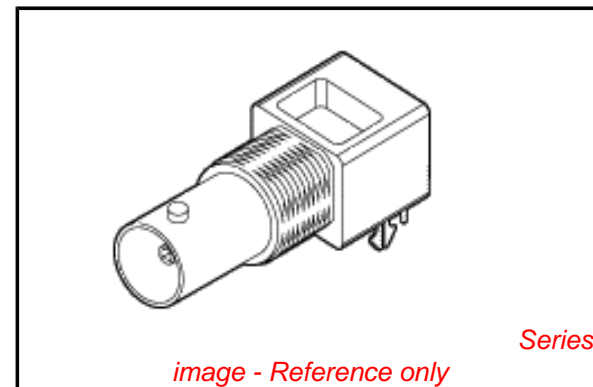

EU RoHS

RoHS Compliant RF Product

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Pb

Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

73101Series