

## Accessories

Description	Type	Order Code	Weight, kg
-------------	------	------------	------------

### Protective membrane

Of transparent, heat and cold resistant rubber.  
Does not harden at low temperatures. Gives IP 67 protection.  
When membrane is used, remove the gasket.

For pushbutton with:

Flush button	<b>KA1-8052</b>	<b>1SFA 616 920 R8052</b>	0.002
Extended button	<b>KA1-8002</b>	<b>1SFA 616 920 R8002</b>	0.002

### Mounting tool

Used for fastening the nut.

	<b>1SFA 616 920 R8015</b>	0.100
--	---------------------------	-------

### 30 mm adaptors

For use when fitting the 22 mm pilot devices in 30 mm mounting holes. (1.5 – 4 mm panels)

Black plastic	<b>KA1-8029</b>	<b>1SFA 616 920 R8029</b>	0.010
Metal	<b>KA1-8030</b>	<b>1SFA 616 920 R8030</b>	0.035

Description	Type	Order Code	Weight, kg
-------------	------	------------	------------

### Lamp changing tool

Fits filament bulbs and LEDs.

<b>KA1-8072</b>	<b>1SFA 616 920 R8072</b>	0.002
-----------------	---------------------------	-------

Description	Order Code	Weight, kg
-------------	------------	------------

### Legend plates

#### Engraved fixed plates with symbol/text

Symbol/text	Legend plate material
-------------	-----------------------

#### For pushbuttons and pilot lights

O	Silver-grey aluminium	<b>SK 615 550-61</b>	0.002
Off	Silver-grey aluminium	<b>SK 615 552-21</b>	0.002
On	Silver-grey aluminium	<b>SK 615 552-22</b>	0.002
Start	Silver-grey aluminium	<b>SK 615 550-44</b>	0.002
Stop	Silver-grey aluminium	<b>SK 615 552-31</b>	0.002

Symbol/text

Centre	Right	Legend plate material
--------	-------	-----------------------

#### For two-position selector switches





O	I	Silver-grey aluminium	<b>SK 615 550-75</b>	0.002
Hand	Auto	Silver-grey aluminium	<b>SK 615 552-31</b>	0.002
Off	On	Silver-grey aluminium	<b>SK 615 552-53</b>	0.002
Stop	Start	Silver-grey aluminium	<b>SK 615 552-55</b>	0.002

Symbol/text

Left	Centre	Right	Legend plate material
------	--------	-------	-----------------------

#### For three-position selector switches

I	O	II	Silver-grey aluminium	<b>SK 615 550-81</b>	0.002
Hand	O	Auto	Silver-grey aluminium	<b>SK 615 550-80</b>	0.002
Slow	Off	Fast	Silver-grey aluminium	<b>SK 615 552-60</b>	0.002

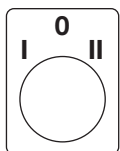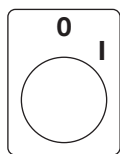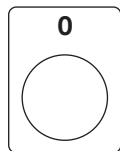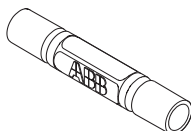

29.6 x 39 mm  
Text height 3 mm