

Profile gasket - HC-B24-SP-RBK - 1407709

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Profile gasket for HEAVYCON EVO supporting base element type B24



Key commercial data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 046356 778039
Weight per Piece (excluding packing)	4.19 g
Custom tariff number	40169300
Country of origin	Poland

Technical data

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

General

Material	NBR
Seal material	NBR
Assembly instructions	The replacement seal should be bonded with Loctite 454 adhesive.
Connection	For HC-EVO-B24....BK housing

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27260704

Profile gasket - HC-B24-SP-RBK - 1407709

Classifications

eCl@ss

eCl@ss 7.0	27440402
------------	----------

ETIM

ETIM 3.0	EC000796
ETIM 4.0	EC000437
ETIM 5.0	EC001181

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approvals submitted


Approval details

EAC

Drawings

Profile gasket - HC-B24-SP-RBK - 1407709

Dimensioned drawing

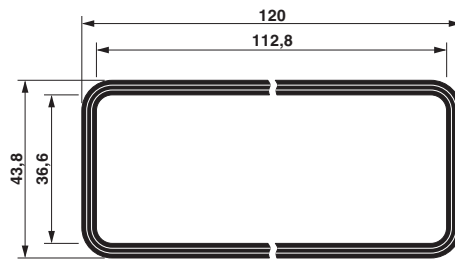

Dimensional drawing

Phoenix Contact 2015 © - all rights reserved
<http://www.phoenixcontact.com>