
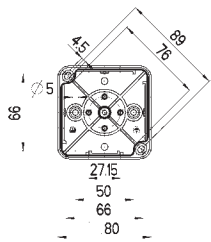


WK 007

80 x 80 x 38 mm

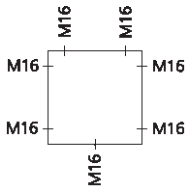

Description

Order No.

Packing Qty

Junction box acc. DIN EN 60670 (VDE 0606), $U_i=400V$, Duroplastic, halogen-free, with IP54 attachment bushes, with blanking plug M16, seal range 6 - 10 mm





WK 007-L
grey, without terminal 402 907 01 60/5

WK 007-2,5²
grey, with screw terminal 5-poles - 2.5 mm², (6 x 1.5² / 4 x 2.5²) 402 407 01 60/5

WK 040

87 x 87 x 45 mm

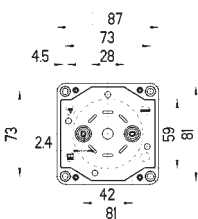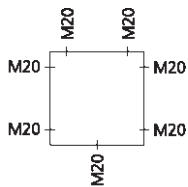

Junction box acc. DIN EN 60670 (VDE 0606), $U_i=690V$, Duroplastic, halogen-free, with IP54 attachment bushes, with blanking plug M20, seal range 8 - 13.5 mm



WK 040-L
grey, without terminal 404 907 01 60/3

WK 040-4²
grey, with screw terminal 5-poles - 4 mm², (6 x 2.5² / 4 x 4²) 404 407 01 60/3