

Mini-Lynx Fast-Start

ML FAST-START 827 E27 11W SLV

0035108

Range features



CE

PRODUCT OVERVIEW

Ordering number	0035108
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Stick
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351087
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	600
Efficacy (Rated) (lm/w)	55
Watt (Nominal) (W)	11
Equivalent watt (W)	50
Voltage (V)	220-240

Mini-Lynx Fast-Start

ML FAST-START 827 E27 11W SLV

0035108

DATA TABLE

General data

Ordering number	0035108
Dry applications use only	Yes
Technology	Compact Fluorescent
Average life (Rated) (h)	10000
Average life (Nominal) (h)	10000
Energy class	A
Energy saving lamp	Yes
Lamp shape	Stick
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351087
E-number FI	4940278
E-number SE	8357538
Long description	
Product name	ML FAST-START 827 E27 11W SLV
Lamp mercury content (mg)	<2.5
Starting time (max) (s)	< 1.0 Sec
Warm-up time to 60% of full light (max) (s)	< 40 s
Control gear required	No
IEC Reference	IEC 60968
IEC Reference 2	IEC 60969
IEC Reference 3	IEC 55015
ILCOS code	FBTH-11/27/1b-E27-48/102
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

Mini-Lynx Fast-Start

ML FAST-START 827 E27 11W SLV

0035108

Optical data

Light colour	827 Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Lumen maintenance at end of nominal life (%)	= 75.0 %
Luminous flux (Rated) (lm)	600
Luminous flux (Nominal) (lm)	600
Chromaticity coordinate Y	0.420
Chromaticity coordinate X	0.463

Electrical data

kWh per 1000 hours burning time	11
Efficacy (Rated) (lm/w)	55
Watt (Nominal) (W)	11
Watt (Rated) (W)	11
Equivalent watt (W)	50
Voltage (V)	220-240
Current (A)	0.085
Lamp power factor	> 0.55

Physical data


Weight (kg)	0.06
Lamp Length (mm) - C/L	102
Max. Lamp Diameter (mm) - D	48
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	11.00 x 5.00 x 5.00
Outer package dimensions (L x W x H) (cm)	25.00 x 11.00 x 13.00

Mini-Lynx Fast-Start

ML FAST-START 827 E27 11W SLV

0035108

TECHNICAL DRAWINGS

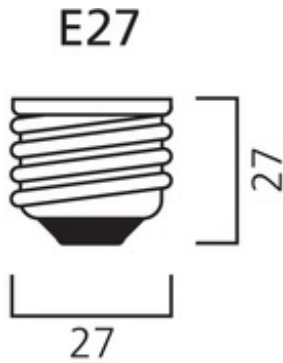

ENERGY LABEL

