


INSTRUCTIONS FOR USE

COMPLEX DESIGN

TNT™ Blue Disposable latex GLOVES

A. Use

These gloves are designed to protect the hands against short contacts from certain chemicals. They are in conformity and are marked as per requirements of the European Directive 89/686/EEC and its Amendments and they are in compliance with the European Standards EN 420 and EN 374.

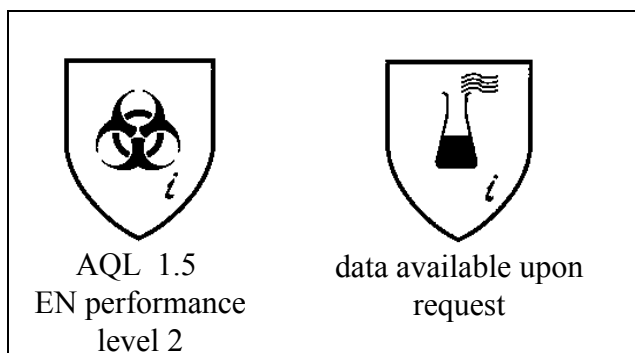

EC-Type examination certificate and EC-Quality Control for the final product by Centexbel Belgium (I.D. 0493).

B. Precautions for use

1. Before usage, inspect the gloves for any defects or imperfections. If in doubt, do not use the gloves, get a new pair.
2. If the gloves are used against chemicals :
 - keep all chemicals from the skin, even if they are thought to be harmless. The gloves should only be used for splash protection or short contact. For more details regarding chemical suitability, please contact the Ansell technical department.
 - if chemicals would get to the skin, wash them off with plenty of water and soap.
 - ensure the chemicals cannot enter via the cuff.
3. The gloves should not be used in applications which require mechanical and/or thermal risks.

C. Ingredients / Hazardous ingredients

Some gloves might contain ingredients which are known to be a possible cause of allergies to sensitised people, hence may develop irritant and/or allergic contact reactions. If allergic reactions would occur, obtain medical advice immediately.

For more information, please contact Ansell's Customer service department.

D. Care instructions

Storage : Keep out from direct sunlight; store in a cool and dry place.
Keep out from sources of ozone or ignition.

Cleaning : The gloves are not designed to be laundered.

E. Disposal

Used gloves may be contaminated with infectious or other hazardous materials.
Dispose of according to Local Authority Regulations. Landfill or incinerate under controlled conditions.

Ansell Healthcare Europe
Internationale Laan 55
1070 Brussels
Belgium

Type	Finish	Colour	Reference	Sizes	Thickness	Length
No Powder	Textured	Blue	92-670	6½-7; 7½-8; 8½-9; 9½-10	0.12 mm	240 mm

Note : The length of the gloves are below the minimum requirements as per EN 420. Hence, these are gloves that 'Fit for special purpose'.


INSTRUCTIONS FOR USE

COMPLEX DESIGN

TNT™ Blue and ProFood Disposable nitrile GLOVES

A. Use

These gloves are designed to protect the hands against short contacts from certain chemicals. They are in conformity and are marked as per requirements of the European Directive 89/686/EEC and its Amendments and they are in compliance with the European Standards EN 420 and EN 374.

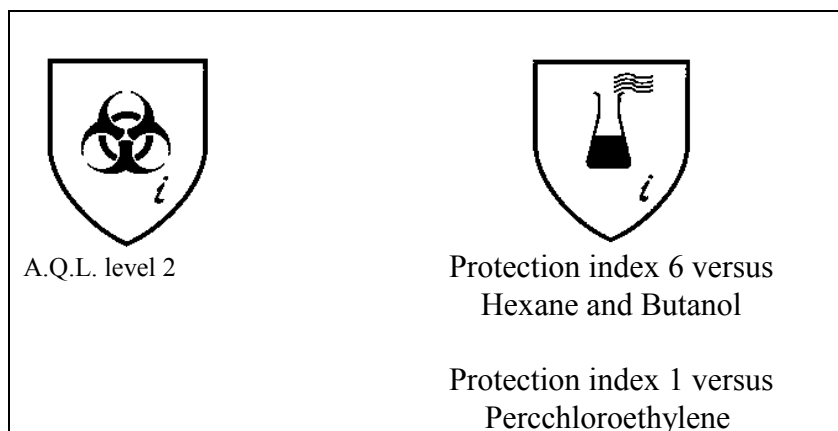

EC-Type examination certificate and EC-Quality Control for the final product by Centexbel Belgium (I.D. 0493).

B. Precautions for use

1. Before usage, inspect the gloves for any defects or imperfections. If the gloves are ripped or punctured during use, dispose them immediately.
If in doubt, do not use the gloves, get a new pair.
2. It is essential to keep all chemicals from the skin, even if they are thought to be harmless. Therefore, use which are rated with a protection index of 6 or with an excellent degradation rating . In all other cases, the gloves should be used for splash protection or short contact only. For more details regarding chemical suitability, please contact the Ansell technical department.
3. Avoid wearing gloves which are dirty on the inside - they will irritate the skin causing dermatitis or worse.
4. Contaminated gloves should be cleaned or washed before removal.
5. Ensure the chemicals cannot enter via the cuff.

6. The gloves DO NOT protect against mechanical or thermal risks.

C. Ingredients / Hazardous ingredients

Some gloves might contain ingredients which are known to be a possible cause of allergies to sensitised people, hence may develop irritant and/or allergic contact reactions. If allergic reactions would occur, obtain medical advice immediately.

The gloves contain Zinc dibutyldithiocarbamate.

For more information, please contact Ansell's Customer service department.

D. Care instructions

Storage : Keep out from direct sunlight; store in a cool and dry place.
Keep out from sources of ozone or ignition.

Cleaning : The gloves are not designed to be laundered.

E. Disposal

Used gloves may be contaminated with infectious or other hazardous materials.
Dispose of according to Local Authority Regulations. Landfill or incinerate under controlled conditions.

Ansell Protective Products
Wijngaardveld 34C
9300 Aalst
Belgium

Type	Finish	Colour	Reference	Sizes	Thickness	Length
Disposable	Smooth	Light blue	92-670	6½-7; 7½-8; 8½-9; 9½-10	0.425 mm	240 mm
		Dark blue	92-465	6-6½; 7-7½; 8-8½; 9-9½		

Note : The length of the gloves are below the minimum requirements as per EN 420. Hence, these are gloves that 'Fit for special purpose'.