

ALUMILINE® SLIM LED FIXTURE

Features

Long Life	Protected against Dust and Splashing Water
Low Power Consumption	Mounting Holes for Ease of Installation
RoHS Compliant	Available in Multiple LED Spacing
No UV Emission	Cool, Neutral, Warm White Light Output
Thermally Optimized	Custom Connectors Available
Low Profile	Low Voltage Operation

A DIM.	B DIM.	Power	Current	Lumen
± 1.2mm (±.05 inch)	mm (inch)	(W)	(mA)	Flux (lm)
310 (12.20)	10 (.40)	2.0	85	150
610 (24.00)	10 (.40)	4.1	170	300
910 (35.83)	10 (.40)	6.1	255	450
1210 (47.64)	10 (.40)	8.2	340	600


310 (12.20)	16.7 (.66)	1.2	51	90
610 (24.00)	16.7 (.66)	2.4	102	180
910 (35.83)	16.7 (.66)	3.7	153	270
1210 (47.64)	16.7 (.66)	4.8	201	360

310 (12.20)	25 (.98)	0.8	34	60
610 (24.00)	25 (.98)	1.6	68	120
910 (35.83)	25 (.98)	2.4	102	180
1210 (47.64)	25 (.98)	3.3	136	240



Accessories

ZPS-2435 24V, 35 Watt Power Supply
 ZPS-2460 24V, 60 Watt Power Supply
 ZDM-01 PWM LED Dimmer
 Note: ZPS-2435 and ZPS-2460 require use of wire nuts for connections.

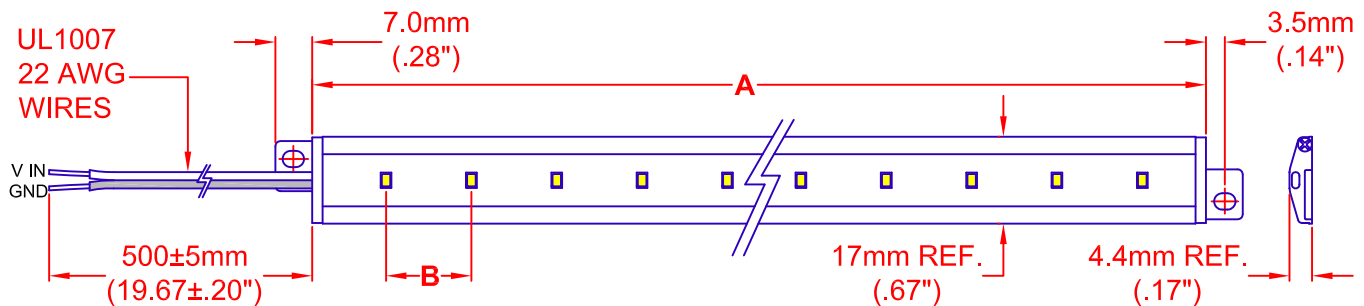

Part Number Ordering Guide

ZLF - DIM. A	COLOR	OPTION	DIM. B	VOLTS
XXXX /	XX /	X /	XX -	XX
0310	W1 - 3500K	X	10 - 10mm	12
0610	W3 - 5300K		16 - 16.7mm	24
0910	W5 - 6000K		25 - 25mm	
1210	W6 - 7500K			

Notes

- Please contact JKL if you prefer this product supplied with a connector.
- Please refer to JKL Application Sheet: JKL-AS-ZLF-ALUMILINE-SLIM for Installation and Power Recommendations.

			METRIC  THIRD ANGLE PROJECTION		DIMENSIONS ARE MILLIMETER (INCH) TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- REF. 2 PL +/- REF. ANGLE +/- REF.		JKL COMPONENTS CORPORATION TITLE ALUMILINE® SLIM LED FIXTURE					
B	ADDED NOTES	8/15/11	DRAWN BY		APP'V'D BY	DATE	SIZE	FSCM NO.	DRAWING NO.	ZLF-MULTI		
A	ADD WIRE TYPE AND SIZE	6/27/11	L. WENGSTROM		L.R.	8/15/11	A	55335				
	RELEASED	12/23/09	- CAD DRAWING - MANUAL REVISIONS NOT PERMITTED				SCALE	RELEASED DATE		REVISION DATE	REV. NO.	SHEET
REV. NO.	DESCRIPTION/ECO NUMBER	APP'V'D DATE					NONE	12/23/09	8/15/11	B	1 OF 1	