
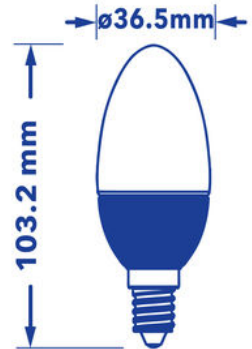


Verbatim LED Candle Frosted E14 4.5W 2700K Warm White 350 LM

- E14 Socket
- 220 - 240 V Voltage
- 20,000 hours Lifetime
- 85% Energy Saving
- Lumen: 350
- Equivalent to 31W incandescent bulb

Product Number	52602
General Data	
Lamp Socket	E14
Electric Data	
Wattage (W)	4.5
Wattage Equivalent (W)	31
Voltage (V)	220 - 240 V
Dimmable	no
Power Factor	0.40
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	103.2
Diameter (in mm)	36.5
Weight (g)	45
Photometric Data	
Luminous Flux (lm)	350
CRI	≥ 80
CCT (K)	2700
Beam Angle (°)	160
Luminous Efficacy (lm/W)	77.8
Lifetime (hrs)	20,000
Switching Cycle	100,000

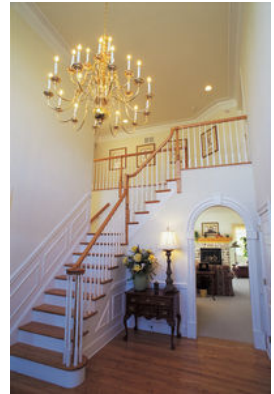

02/07/2014

Energy Rating



Technical Packaging Details

Barcode

023942526025

EAN 128

(02)00023942526025(37)04(91)204

EAN 14

50023942526020

Pack Dimensions(HxWxL)

178 x 118 x 45

Pack Weight

79

MOQ

4

Carton Dimensions (HxWxL)

195 x 104 x 253

Cartons/Pallet

120

Layers/Pallet

4

Units/Pallet

480

02/07/2014