

Mini-Lynx Fast-Start

ML FAST-START 827 E27 8W SLV

0035136

Range features



CE

PRODUCT OVERVIEW

Ordering number	0035136
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Stick
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 3U Stick
EAN code	5410288351360
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	450
Efficacy (Rated) (lm/w)	56
Watt (Nominal) (W)	8
Equivalent watt (W)	42
Voltage (V)	220-240

Mini-Lynx Fast-Start

ML FAST-START 827 E27 8W SLV

0035136

DATA TABLE

General data

Ordering number	0035136
Dry applications use only	Yes
Technology	Compact Fluorescent
Average life (Rated) (h)	10000
Average life (Nominal) (h)	10000
Energy class	A
Energy saving lamp	Yes
Lamp shape	Stick
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 3U Stick
EAN code	5410288351360
E-number FI	4940293
E-number SE	8357533
Long description	
Product name	ML FAST-START 827 E27 8W SLV
Lamp mercury content (mg)	<2.5
Starting time (max) (s)	< 1.50 Sec
Warm-up time to 60% of full light (max) (s)	< 40 s
Control gear required	No
IEC Reference	IEC 60968
IEC Reference 2	IEC 60969
IEC Reference 3	IEC 55015
ILCOS code	FBTH-08/27/1b-E27-44/112
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

Mini-Lynx Fast-Start

ML FAST-START 827 E27 8W SLV

0035136

Optical data

Light colour	827 Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Lumen maintenance at end of nominal life (%)	= 75.0 %
Luminous flux (Rated) (lm)	450
Luminous flux (Nominal) (lm)	450
Chromaticity coordinate Y	0.420
Chromaticity coordinate X	0.463

Electrical data

kWh per 1000 hours burning time	8
Efficacy (Rated) (lm/w)	56
Watt (Nominal) (W)	8
Watt (Rated) (W)	8
Equivalent watt (W)	42
Voltage (V)	220-240
Current (A)	0.070
Lamp power factor	> 0.55

Physical data


Weight (kg)	0.05
Lamp Length (mm) - C/L	112
Max. Lamp Diameter (mm) - D	44
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	12.00 x 4.50 x 4.50
Inner package dimensions (L x W x H) (cm)	24.00 x 15.00 x 10.40
Inner package net weight (kg)	0.52
Outer package dimensions (L x W x H) (cm)	25.00 x 16.50 x 54.50

Mini-Lynx Fast-Start

ML FAST-START 827 E27 8W SLV

0035136

TECHNICAL DRAWINGS

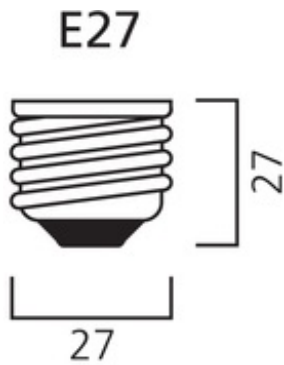

ENERGY LABEL

