 





- *Transformer to IEC 61558-2-1, DIN EN 61558-2-1, VDE 0570 part 2-1 (without VDE-Approval)



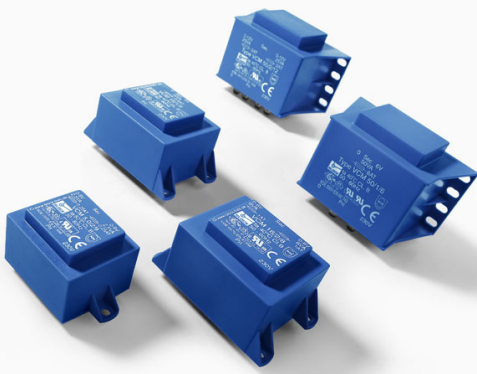

VCM 25/1/24

PCB transformer with mounting brackets



Input data

Input voltage	230 V
Frequency range	50 - 60 Hz
No-load loss (typ.)	2.5 W

Output data

Output voltage	24 V
No-load voltage (ca. x factor)	1.12
Efficiency	82 %
Power	25.0 VA

Standards and security

Approvals	C-UL-US, ENEC 10 (VDE)
Short circuit strength	non-short-circuit proof
Protection index	IP 00
Safety class (prepared)	II
Ambient temperature max.	40 °C
Class of Insulation System	VDE=B, UL=105
Test voltage	5000 V, 50 Hz

Mechanical data

Type	encapsulated
Core type 2	EI 60/25,5
Terminals	pins for pcb
Fixing method	Fixing points on the case
Pin (ø)	0,8 mm
Weight	0.61 kg

Order numbers

Order Number	VCM 25/1/24
--------------	-------------

BLOCK Transformatoren-Elektronik GmbH
 Max-Planck-Straße 36-46
 27283 Verden
 Germany
 Phone +49 4231 678-0
 Fax +49 4231 678-177