


# AXK 90120

## Dimensions

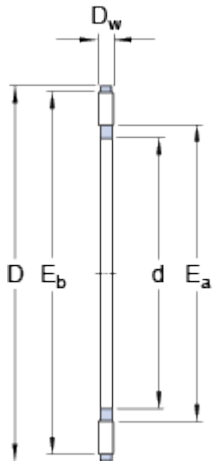

$d$		90	mm
$D$		120	mm
$D_w$		4	mm
$E_a$	min.	94	mm
$E_b$	max.	118	mm

## Calculation data

Basic dynamic load rating	$C$	65.5	kN
Basic static load rating	$C_0$	405	kN
Fatigue load limit	$P_u$	49	kN
Reference speed		1500	r/min
Limiting speed		3000	r/min

## Mass

Mass roller and cage thrust assembly		0.086	kg
--------------------------------------	--	-------	----

## Appropriate products

Universal washer	LS 90120
Thin universal washer	AS 90120
Shaft washer	WS 81118
Housing washer	GS 81118