

Mini-Lynx Fast-Start

ML FAST-START 840 E27 11W SLV

0035111

Range features



CE

PRODUCT OVERVIEW

Ordering number	0035111
Technology	Compact Fluorescent
Light colour	840 Cool White
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Stick
Lamp finish	frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351117
CRI (Ra)	80
Colour temperature (K)	4000
Luminous flux (Rated) (lm)	600
Efficacy (Rated) (lm/w)	54.5
Watt (Nominal) (W)	11
Equivalent watt (W)	50
Voltage (V)	220-240

Mini-Lynx Fast-Start

ML FAST-START 840 E27 11W SLV

0035111

DATA TABLE

General data

Ordering number	0035111
Dry applications use only	Yes
Technology	Compact Fluorescent
Average life (Rated) (h)	10000
Average life (Nominal) (h)	10000
Energy class	A
Energy saving lamp	Yes
Lamp shape	Stick
Lamp finish	frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351117
E-number FI	4940280
E-number SE	8357540
Long description	
Product name	ML FAST-START 840 E27 11W SLV
Lamp mercury content (mg)	<2.5
Starting time (max) (s)	< 1.0 Sec
Warm-up time to 60% of full light (max) (s)	< 40 s
Control gear required	No
IEC Reference	IEC 60968
IEC Reference 2	IEC 60969
IEC Reference 3	IEC 55015
ILCOS code	FBTH-11/40/1b-E27-48/102
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

Mini-Lynx Fast-Start

ML FAST-START 840 E27 11W SLV

0035111

Optical data

Light colour	840 Cool White
CRI (Ra)	80
Colour temperature (K)	4000
Lumen maintenance at end of nominal life (%)	= 75.0 %
Luminous flux (Nominal) (lm)	600
Luminous flux (Rated) (lm)	600
Chromaticity coordinate X	0.38
Chromaticity coordinate Y	0.38
Rated lumen maint. factor at 6000 h	= 80.0 %

Electrical data

kWh per 1000 hours burning time	11
Efficacy (Rated) (lm/w)	54.5
Watt (Nominal) (W)	11
Watt (Rated) (W)	11
Equivalent watt (W)	50
Voltage (V)	220-240
Current (A)	0.085
Lamp power factor	> 0.55

Physical data


Weight (kg)	0.06
Lamp Length (mm) - C/L	102
Max. Lamp Diameter (mm) - D	48
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	11.00 x 5.00 x 5.00
Outer package dimensions (L x W x H) (cm)	25.00 x 11.00 x 13.00

Mini-Lynx Fast-Start

ML FAST-START 840 E27 11W SLV

0035111

TECHNICAL DRAWINGS

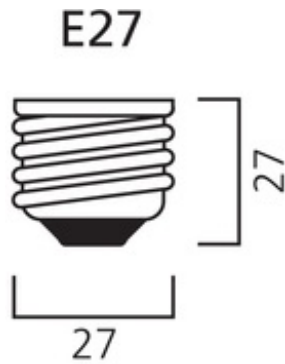

ENERGY LABEL

