


## Datasheet

**RS 36 Core Unscreened Industrial Cable, PVC Sheath, 10.1mm OD, 0.22 mm<sup>2</sup> CSA 1 A, 440 V, 100m**

**Stock Number - 660-4077**

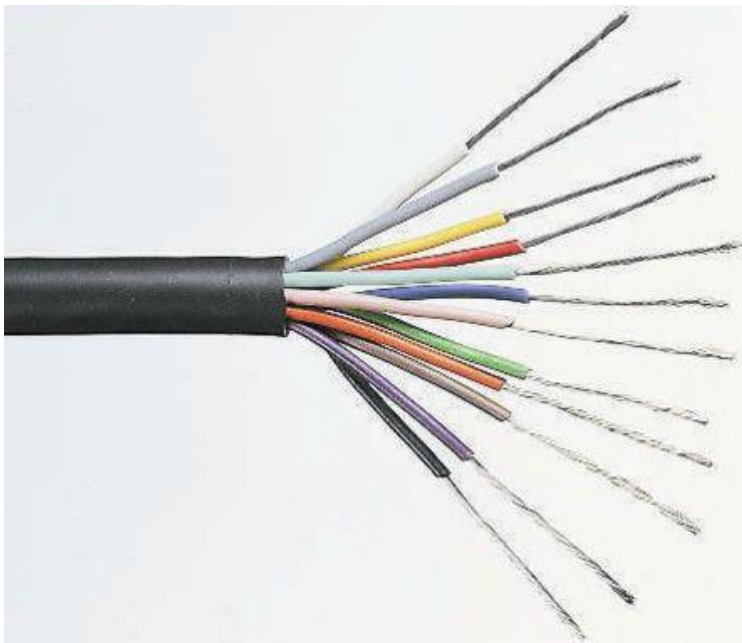

### Description:

**Rated Temperature (oC): -20 ~ 80**

**Rated Voltage (V):440**

**Flammability Test: IEC60332-1**



**Construction:**

**Conductor:**Tinned Copper

**Conductor Dia. (mm):** 0.20±0.008 x 7

**Insulation:** PVC

**Insulation Dia. (mm):** 1.2±0.05 x 36C

**Filler:** 1.2 PVC Strip

**Tape:** Mylar Spiral

**Coverage:**≥115%

**ID Thread :** Green, White/Green

**A rip cord :** 210 D

**Jacket:** FR-PVC

**Outer Dia. (mm):** 9.8±0.2

**Colour:**

**The colour of the insulation:** Red , Blue , Green ,  
Yellow ,  
White , Black , Brown , Violet , Orange , Pink , Light  
Green ,  
Grey , Red/Blue , Green/Red , Yellow/Red ,  
White/Red ,  
Red/Black, Red/Brown, Yellow/Blue , White/Blue ,  
Blue/Black,  
Orange/Blue , Green/Blue , Grey/Blue ,  
Yellow/Green ,  
White/Green, Green/Black, Orange/Green,  
Grey/Green,  
Yellow/Brown, White/Brown, Brown/Black,  
Grey/Brown,  
Yellow/Violet, Violet/Black, White/Violet

**The jacket colour:** Black

**Marking(3times/m):**

RS 6604077 7 - 2 – 36A

**Performance:**

**Electrical Characteristics:**

**Max.Conductor DC Resistance at 20°C (  $\Omega$ /Km ) :**

<92

**Min.Insulation DC Resistance at 20°C (  $M\Omega$ \*KM ) :**

>200

**Current Rating : 1 A**

