



Deep groove ball bearings, single row, unsealed

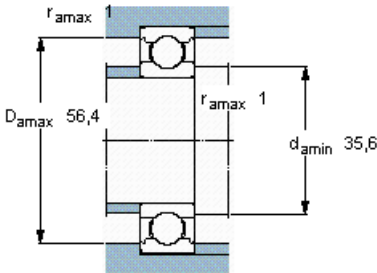

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
30	62	16	20,3	11,2	0,475	24000	15000	0,20	6206 *

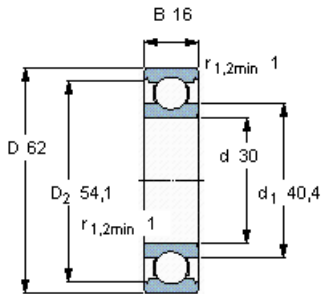

Calculation factors

k_f 0,025
 f_0 14