


ROSHNI AC PROCESS SOUNDERS

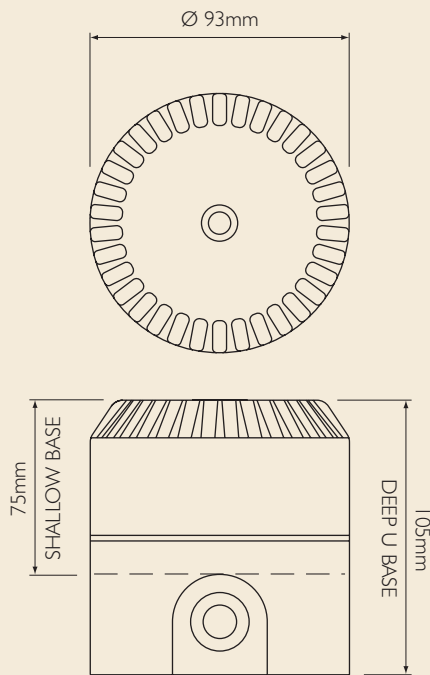

Specification

| | |
|----------------|-----------------------|
| Voltage | 15V to 30Vac / dc |
| Current | 25mA ac / 16mA dc |
| Sound Output | 103dB(A) typical @ 1m |
| Tones | 32 |
| Volume Control | 20dB variation |
| Monitoring | N/A |
| Temperature | - 25°C to + 70°C |
| IP rating | IP65 |
| Weight | 0.22Kg |
| Construction | FR ABS |
| Colour | Red or White |

The Roshni AC operates from either low voltage AC or DC supplies without modification and is suitable for use in general signalling or as a process plant alarm. The sounder fits all Fulleon bayonet bases.

- 24Vac / dc OPERATION
- IP65 PROTECTION
- 32 TONES
- HIGH OUTPUT
- LOW CURRENT CONSUMPTION
- LOCKABLE BASE