



# Reflective types

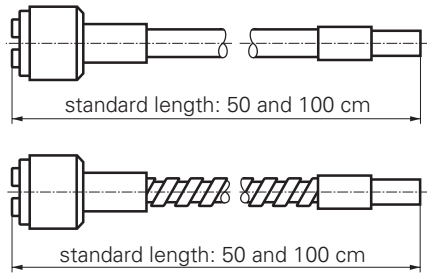

Available in either plastic or metal sheaths. The reflective types come in standard lengths of 50 and 100 cm with randomly assembled fibers. Other lengths on request.

**Adapter and cap nut must be ordered separately when used with series 30**

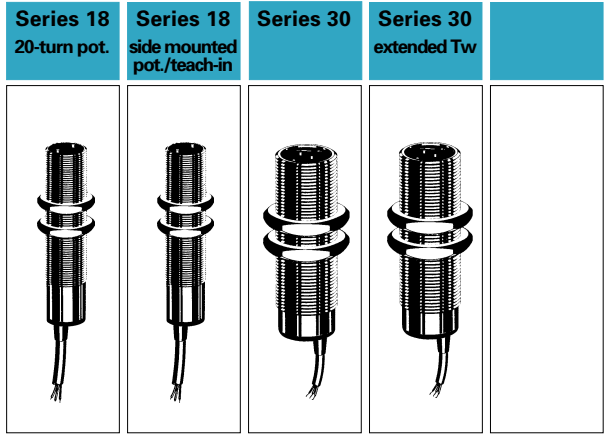

Fiber diameter 2 x 3 mm <sup>2</sup>	
Sheath material : PUR ø 6 mm	Part number
	<b>FUE 050A2008</b> (length 50 cm)
	<b>FUE 100A2008</b> (length 100 cm)
	<b>FUE 050A1008</b> (length 50 cm)
	<b>FUE 100A1008</b> (length 100 cm)

TW = sensing distance				
60 mm	150 mm	100 mm	210 mm	
55 mm	150 mm	100 mm	200 mm	
60 mm	150 mm	100 mm	210 mm	
55 mm	150 mm	100 mm	200 mm	

Fiber diameter 2 x 3 mm <sup>2</sup>	
Sheath material: brass chromium plated ø 6 mm	Part number
	<b>FUF 050A2003</b> (length 50 cm)
	<b>FUF 100A2003</b> (length 100 cm)
	<b>FUF 050A1003</b> (length 50 cm)
	<b>FUF 100A1003</b> (length 100 cm)

TW = sensing distance				
60 mm	150 mm	100 mm	210 mm	
55 mm	150 mm	100 mm	200 mm	
60 mm	150 mm	100 mm	210 mm	
55 mm	150 mm	100 mm	200 mm	