

3478UAR100P62 red

EAN 4031582369717


Fixed castor, Fork made of pressed steel, bright zinc plated, blue passivated, wheel axle with nut, plate fitting.

Wheel centre made of Polyamide, Tread: Polyurethane, roller bearing

Technical Data

Wheel diameter	100 mm
Width of Tread	32 mm
Size of Plate	103 x 85 mm
Plate hole centres	80/77 x 60 mm
Plate hole	9 mm
Overall height	128 mm
Temperature	- 40 / + 80 °C
Standard	EN 12532
Weight	0.526 kg
Hardness of tread	D 60 Shore
Load capacity	150 kg
Load capacity (static)	300 kg

Roll performance	+	+	+	+	+
Movement noise	+	+	+	+	+
Attrition	+	+	+	+	+
Corrosion resistance	+	+	+	+	+

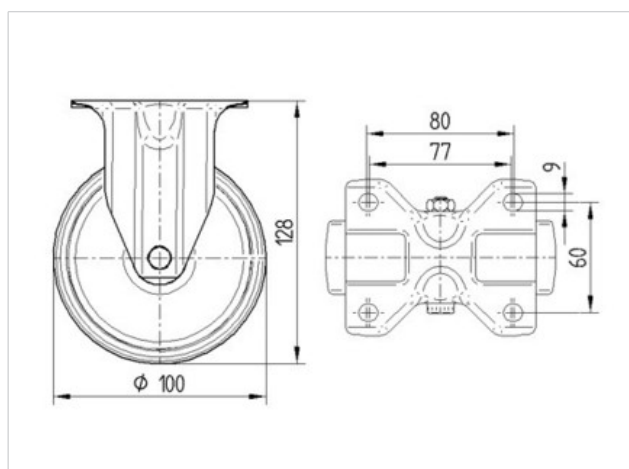

3478UAR100P62 red

EAN 4031582369717

