


Expression Photo XP-55



DATASHEET

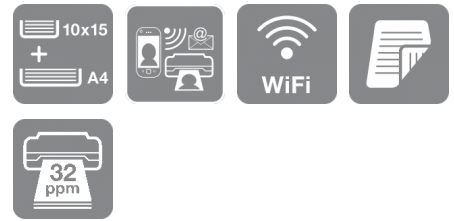

Ideal for photo enthusiasts looking for superior photo printing. The Expression Photo XP-55 uses Claria Photo HD ink to ensure photos will last for generations¹. The addition of Wi-Fi and mobile printing with Epson Connect² make sharing your creations quick and easy. You also benefit from dual paper trays and CD/DVD printing capability.

Superior results

The XP-55 has been specially designed for photography enthusiasts after top-quality results. It uses Epson's own Claria Photo HD ink, an exceptional, 6-colour individual inkset for superior-quality, long-lasting photographs that can last for a stunning 300 years in a photo album¹.

Mobile printing

Epson Connect consists of Epson iPrint² – for easy wireless printing from smartphones and tablets; Epson Creative Print² – print photos directly from Facebook, and Epson Email print² – print from anywhere in the world by emailing photos and documents directly to the printer. AirPrint³ is also supported.

Wireless connectivity


Print wirelessly from around the house. Automatic Wi-Fi set-up⁴ makes configuring laptops and computers to print wirelessly extremely easy. The XP-55 is also Wireless PictBridge-ready, so you can print straight from compatible cameras.

Versatile printing

Dual paper trays, one for A4 and one for photo paper, and a speciality media feed for thicker card makes for easy, versatile printing. Printing directly on to suitable CD/DVDs is also possible. Double-sided printing will help save money and is kinder to the environment.

KEY FEATURES

- **High-quality photo printing**
Claria Photo HD inks for exceptional, long-lasting photos
- **Flexible**
Wi-Fi connectivity and easy mobile printing.
- **Dual paper trays**
One for A4 and another for photo paper
- **Versatile media**
Prints on a range of media including thick card and CD/DVDs
- **Fast results**
Prints a photo in just 10 seconds⁵

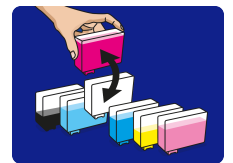

PRODUCT SPECIFICATIONS

TECHNOLOGY	
Printing Method	Epson Micro Piezo™ print head
Nozzle Configuration	180 Nozzles black, 180 Nozzles per colour
Minimum Droplet Size	1.5 pl, With Variable-Sized Droplet Technology
Ink Technology	Claria™ Photo HD Ink
Printing Resolution	5,760 x 1,400 dpi
All-in-One Functions	Print
PRINT	
Printing Speed ISO/IEC 24734	9.5 Pages/min Monochrome, 9 Pages/min Color
Maximum Printing Speed	10 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper), 32 Pages/min Color (plain paper), 32 Pages/min Monochrome (plain paper)
Colours	Magenta, Yellow, Cyan, Light Cyan, Black, Light Magenta
For detailed information on printing speeds please visit http://www.epson.eu/testing .	
PAPER / MEDIA HANDLING	
Number of paper trays	2
Paper Formats	A4, A5, A6, B5, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter, 10 x 15 cm, 13 x 18 cm, 16:9, Legal
Duplex	Yes
Rear paper path (special media)	Yes
Media Handling	Automatic duplex, Borderless print, CD/DVD print, Rear specialty media feed
Print Margin	0 mm top, 0 mm right, 0 mm bottom, 0 mm left (Wherever margin is defined. Otherwise 3mm top, left, right, bottom.)
Paper Tray Capacity	100 Sheets Standard, 20 Photo Sheets
GENERAL	
Product dimensions	390 x 338 x 141 mm (Width x Depth x Height)
Product weight	5 kg
Noise Level	5.3 B (A) with Epson Premium Glossy Photo Paper / Photo RPM mode - 39 dB (A) with Epson Premium Glossy Photo Paper / Photo RPM mode
Compatible Operating Systems	Mac OS X 10.6.8 or later, Windows 7, Windows 8, Windows Vista, Windows XP, Windows XP x64
Interfaces	WiFi, USB, Ethernet
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA PSK (AES)
Mobile and Cloud printing services	Epson Connect (iPrint, Email Print, Remote Print Driver), Apple AirPrint, Google Cloud Print
Energy Use	ENERGY STAR® qualified, 1.2 W (sleep mode), 19 W (printing)
Included Software	Epson Easy Photo Print, Epson Print CD
Supply Voltage	AC 220 V - 240 V

LOGISTICS INFORMATION

SKU	C11CD36401
EAN code	8715946542669
Dimensions Single Carton	425 x 475 x 220 mm
Carton Weight	6.5 Kg
Multiple Order Quantity	1 Units
Country of Origin	Indonesia
Pallet Size Euro	18 Units
Pallet Size Block	36 Units



For more information please contact:

Telephone: 01952 607111 (UK)+
01 436 7742 (Republic of Ireland)
E-mail: enquiries@epson.co.uk
Chat: etalk.epson-europe.com
Fax: 0871 222 6740
+ Local call rate.

Web: www.epson.co.uk
www.epson.ie

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.

Expression Photo XP-55

WHAT'S IN THE BOX

- Software (CD)
- Setup guide
- Power cable
- Main unit
- Individual Ink Cartridges

INK CARTRIDGE COMPATIBILITY



INK YIELD DATA

	Elephant 24	Elephant 24XL
Black	240 pages*	500 pages*
Cyan, Magenta, Yellow, Light Cyan	360 pages*	740 pages*

* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. Print permanence ratings are based on accelerated testing of prints on specialty media stored in archival sleeves in album storage. Actual print stability will vary according to the media, printed image, display conditions, light intensity, humidity, and atmospheric conditions. Epson does not guarantee longevity of prints. 2. Epson iPrint and Epson Creative Print require a wireless connection and the Epson printing apps. Email print and Epson Remote Print Driver requires an internet connection. For more information, supported languages and devices, please visit www.epsonconnect.eu 3. AirPrint-enabled printers work with iPad (all models), iPhone (3GS or later), and iPod touch (3rd generation or later) running the latest version of iOS. 4. Automatic set-up compatible with Windows 8, Windows 7, Windows Vista and Mac OS. Initial Wi-Fi set-up requires a USB cable for Windows XP users - not included 5. For test conditions visit www.epson.eu/testing

EPSON®