
CENTRA A FR 60 W 120 V B22D

SPECIAL CENTRA Standard A | Incandescent lamps, classic bulb shape, impact-resistant



Product benefits

- Particularly shockproof and resistant to vibration

Product features

- Additional filament supports



Technical data

Electrical data

Nominal wattage	60.00 W
Nominal voltage	120 V
Rated wattage	60.00 W


Photometrical data

Luminous flux	505 lm
Color rendering index Ra	100
Color rendering index Ra	100

Light technical data

Starting time	0.0 s
---------------	-------

Dimensions & weight

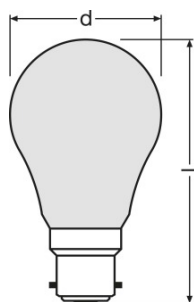

Diameter	60.0 mm
Length	106.0 mm
Overall length	106.0 mm
Outer bulb	A60

Lifespan

Nominal lamp life time	1000 h
Rated lamp life time	1000 h

Additional product data

Base (standard designation)	B22d
Lamp mercury content	0.0 mg
Mercury-free	Yes

Product datasheet

Country specific categorizations

ILCOS	IAA/F-60-120-B22D-60
-------	----------------------

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4050300615080	CENTRA A FR 60 W 120 V B22D	Shipping carton box 25	300 mm x 116 mm x 300 mm	10.44 dm ³	1483.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.