



AMPERE-METER, DIGITAL AC 25A +999/5A,
DEPTH=70MM FOR DIRECT AND TRANSF.CONNEC.

Similar to image

Technical data:

Type of voltage		AC
Number of width units		2
Mounting type / series installation		Yes
Type from device		DIN rail
Height	mm	90
Width	mm	36
Metering range current	A	0 ... 40
Product quality / calibrated		No
Product feature		
• Transducer connection		No
• dial illumination		No
• Drag pointer		No
Current / as full-scale value	A	1,000
Type of built-in ammeter		Other

Certificates/approvals:



Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/7KT1120>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/7KT1120/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=7KT1120

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

[Datanorm GAEB81](#) [GAEB83](#) [RTF](#) [TXT](#)

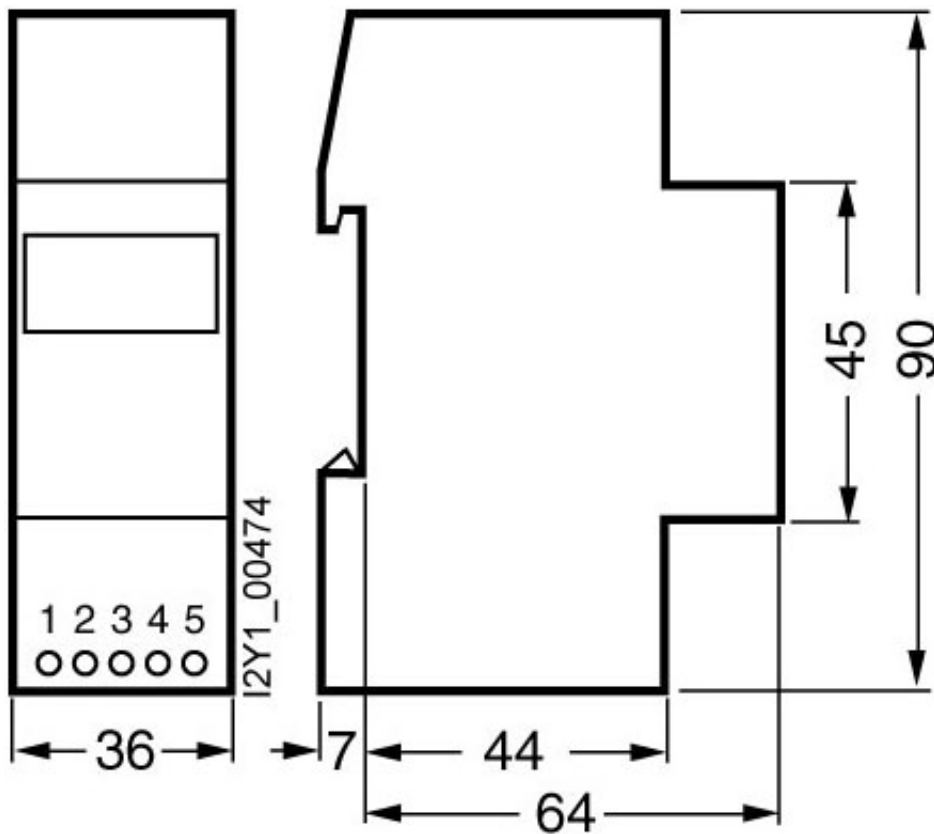

last change:

Aug 12, 2014