

T 206



Euromas
 Enclosure, ABS

Order no.: 03206000

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request

Protection class

Depending on the model: IP 65 or IP 66/DIN EN 60529; IP 67 available on request for some sizes.


Enclosure material

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: SV = version with quick-release fastener.

IP = Ingress protection acc. to DIN EN 60529

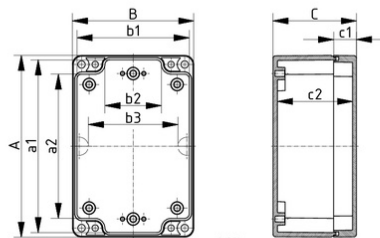

A	65 mm
B	50 mm
C	35 mm
a1	59,4 mm
a2	43 mm
b1	44 mm
b2	27,7 mm
c1	10 mm
c2	29,5 mm

Technical drawings

Catalogue drawing in DXF format:

[03206000_T-206.dxf](#) (580 KB)

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[03206000_T-206-G.dxf](#) (300 KB)

Catalogue drawing in PDF format:

[03206000_T-206.pdf](#) (71 KB)

Chapter download

[Euromas_ABS_PC_GB.pdf](#) (338 KB)


Accessories



Mounting plates, laminated paper (Pertinax), galvanised steel for version 260

22000200 [M](#)

For EM/ET 206, M/T 206

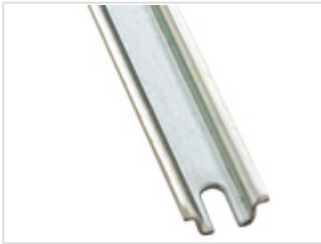

DIN rails DIN EN 60715 TH 15

22001710 [TS 15](#)

For M/T 206



Threaded inserts for mounting bosses

59002810 [DODGE M3x6,5](#)

ND = 4.0 x 6.5

59002820 [DODGE M4x9,5](#)

ND = 5.4 x 9.5

* = Available on request