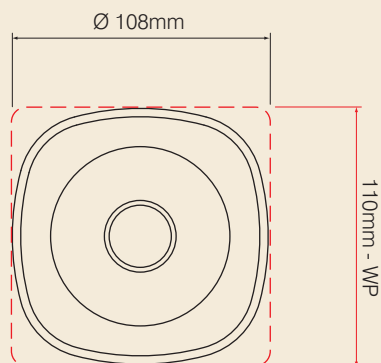


Specification

Voltage	9 - 28Vdc
Current	240mA max (Typical Tone 3)
Sound Output	114dB(A) (Typical Tone 3) 120dB(A) (Typical Tone 6)
Tones	32
Volume Control	20dB
Monitoring	Reverse polarity
Temperature	- 10°C to + 55°C - 25°C to + 70°C (WP)
Protection	IP21C IP66 (WP)
Construction	ABS, PC lens
Weight	0.58Kg 0.68Kg (WP)
Colours	Red or white

Symphoni HO

HIGH OUTPUT SOUNDER

Where a very loud sounder is needed the Symphoni High Output will provide the answer. Producing levels of up to 120dB(A) this sounder can be used in open areas or in situations having higher than normal background noise levels. Despite its high output the unit is very efficient and offers relatively low current consumption.

- VERY HIGH OUTPUT
- AUTOMATIC SYNCHRONISATION
- SWITCH SELECTABLE TONES
- VOLUME CONTROL
- SECOND TONE FOR TWO STAGE ALARMS
- WP VERSION SUITABLE FOR OUTDOOR USE