


Professionally approved products.

Datasheet

Flat 175V, 250mA Reed Switch

RS Stock number [339-213](#)

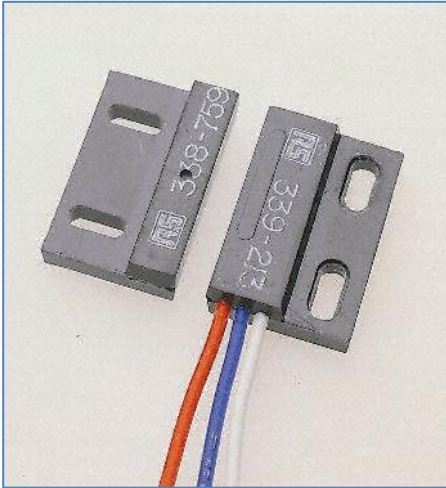

Description:

Light Duty, Moulded case with 2 slotted fixing holes

Breakdown volts: 450dc (N/O); 200dc (C/O)

Operating temperature range -40 → 105 °C

PTFE Cable length: 304mm

Note:

Actuator magnet must be ordered separately, see Stock No. 338-759

Specification:

- Contact Resistance 200mΩ
- Depth 3.42mm
- Length 19.05mm
- Maximum AC Voltage 175V
- Maximum Current 250 mA
- Maximum DC Voltage 250V
- Maximum Operating Temperature +200°C
- Minimum Operating Temperature 0°C
- Switch Shape Flat
- Terminal Type Screw
- Total Length 19.05mm
- Width 28.57mm

Dimensions:

