



ENGLISH


Datasheet

AC Axial Fan, 80 x 80 x 38mm, 52.7m³/h, 12W, 230 V ac (OA80 Series)

RS Stock 619-7015



Dimensions: (mm)

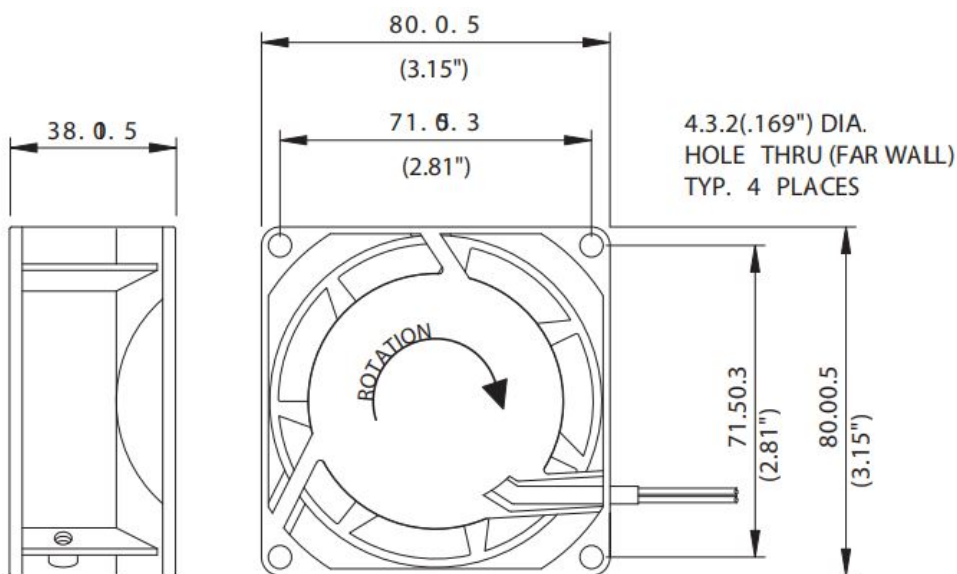

M4 GROUND HOLE



Specifications

- Frame: Die cast Aluminium
- Impeller: PBT , UL94V-0 Thermoplastic
- Motor: Shaded Pole , Impedance Protected
- DIELECTRIC STRENGTH :1 minute@1500 VAC, 50/60 Hz
- LIFE EXPECTANCY (L10) :Ball Bearing 60,000 Hours
- Operating Temperature :-20C ~ +80C
- Safety Approvals: UL/CUL, TUV, CE

RS Part No.	Orion Part No.	Speed	Airflow	Noise	Volts	Voltage	Current	Connection Type
6196983	OA4715-12-1TB	3000	31	36	115	80~130	12	Terminal
6196977	OA4715-23-1TB	3000	31	36	115	80~130	12	Terminal
6196999	OA80AP-11-1WB	3000	31	36	115	80~130	12	Terminal
6197015	OA80AP-22-1TB	3000	31	36	230	160~260	12	Terminal
6197009	OA80AP-22-1WB	3000	31	36	230	160~260	1	Terminal