

Project..... Comments.....

Fixture Type..... Prepared By.....

**Product Description:**

High output LED lamp. Unique far infrared ceramic thermal management. True GU10 size. High colour rendering index (RA) 80. Average lifetime 40,000 hours. 3 years guarantee.

**Product Image & Dimensions:**

 


Overall Diameter	50 mm
Overall Length	55 mm
Overall Height	55 mm

**Product Specifications:**

- Lamp Type: GU10
- Lamp Base: GU10
- Input Voltage (Min): 220 V
- Input Voltage (Max): 240 V
- Input Voltage Type: AC
- Dimmable: No
- Beam Angle: 38 °
- Lifespan: 40000 hrs
- No. of LEDs: 3
- Overall Diameter: 50 mm
- Overall Length: 55 mm
- Overall Height: 55 mm
- Guarantee: 3 Years

**Compliance & Approvals:**



**SKU Table and Ordering:**

SKU Code	Wattage	Colour Temperature	Lumens	Candelas	EAN	Qty
AU-GU106/30	6 W	3000 K	330 lm	570 cd	5055155483876	<input type="text"/>
AU-GU106/40	6 W	4000 K	360 lm	620 cd	5055155483883	<input type="text"/>

**Warranty:**

For available warranty information for this product, please visit:

<http://gb.auroralighting.com/Products/Lamps/Firetec-LED-Lamps/240V-GU10/240V-GU10-6W-Non-dimmable-LED-Lamp.aspx>

**UK Sales**

16 Alban Park  
Hatfield Road, St. Albans  
United Kingdom  
PH: +44 (0) 1727 83 66 11  
FX: +44 (0) 1727 83 66 22


**UK Distribution**

Apex Park, 6 Little Burrows  
Burrowfields, Welwyn Garden City  
AL7 4SW  
United Kingdom  
PH: +44 (0) 1707 35 18 20  
FX: +44 (0) 1727 35 18 21

**Output Data:**

---

**AU-GU106/30**

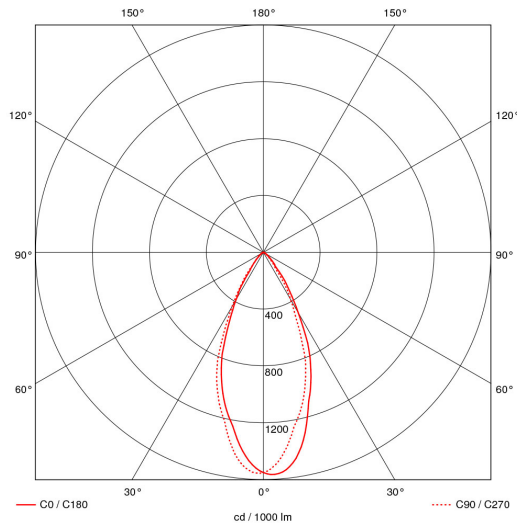

**Warranty:**

For available warranty information for this product, please visit:

<http://gb.auroralighting.com/Products/Lamps/Firetec-LED-Lamps/240V-GU10/240V-GU10-6W-Non-dimmable-LED-Lamp.aspx>

**UK Sales**

16 Alban Park  
Hatfield Road, St. Albans  
United Kingdom  
PH: +44 (0) 1727 83 66 11  
FX: +44 (0) 1727 83 66 22

**UK Distribution**

Apex Park, 6 Little Burrows  
Burrowfields, Welwyn Garden City  
AL7 4SW  
United Kingdom  
PH: +44 (0) 1707 35 18 20  
FX: +44 (0) 1727 35 18 21