


DG PCB 275 (952 610)

- Integration of DEHNguard protection modules in the PCBs of electronic / electrical devices
- Easy and flexible use for all circuit configurations
- Coded base part and protection module ensure against installing an incorrect module



Figure without obligation

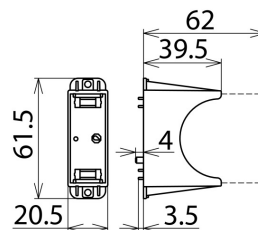

Dimension drawing DG PCB 275

Single-pole base for DEHNguard modules to be mounted on the PCBs of devices.

Type	DG PCB 275
Part No.	952 610
Associated protection module	DG MOD 275 (Part No. 952 010)
Max. continuous a.c. voltage (module)	275 V
Operating temperature range (T _U)	-40 °C ... +80 °C
Mounting	directly soldered into PCB
Enclosure material	thermoplastic, red, UL 94 V-2
Degree of protection	IP 20 (protection module plugged in)
Weight	18 g
Customs tariff number	85366930
GTIN	4013364149816
PU	72 pc(s)

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.